


适用于 PSK 的 PSU 前面板，单路输出，3 U，6 HP，屏蔽，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

21005-475

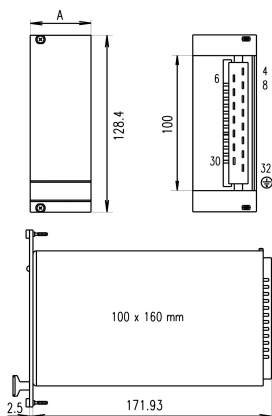

适用于 nVent SCHROFF 19"

兼容电源的前面板。带垂直凹槽的扁平前面板，适用于不锈钢 EMC 接触条。

认证



功能

前面板，铝，正面阳极氧化，背面导电，带适用于 EMC 接触条的垂直插槽

产品属性

产品类型: 前面板

附件类型: 前面板

材料: 铝

正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
机架高度: 3U
高度: 128.4mm
机架宽度: 6HP
宽度: 30.14mm
深度: 2.5mm
包装数量: 1
完成: 阳极氧化
Net Weight: 0.051kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE