


# 前面板不锈钢 EMC 屏蔽套件，适用于 U 型前面板，6 U，100 件

物料号

**21102-108**

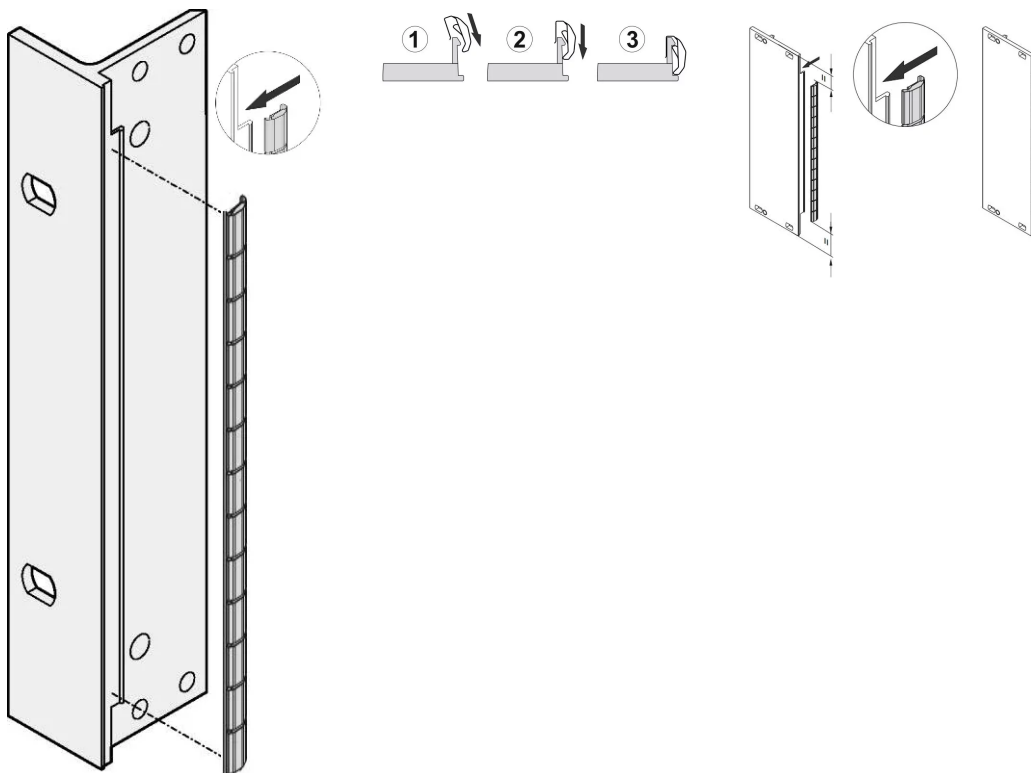

防锈 EMC 垫片可插入 U 型前面板右侧的插槽。

The gasket will be clipped onto the right front panel bracket, the 19" bracket or rear profile of the subrack

## 功能

不锈钢 EMC 垫片，适用于 SCHROFF U 型前面板，提供卓越的屏蔽效能和广泛的温度范围（从 -200 至 +160°C）。

安装简单——将垫片插入右侧前面板支架，19 英寸支架或插箱的尾型槽

温度范围从 -200 至 +160°C。

## 产品属性

机架高度: 6U

包装数量: 100

材料: 不锈钢

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; 框架式插入单元

产品类型: 屏蔽套件

机架宽度: 100HP


搭配: 插箱; 仪器箱; 前面板

Gross Weight: 0.182kg

## 其他产品详情

需要防锈的 EMC 垫片来为前面板提供屏蔽防护。

## 图

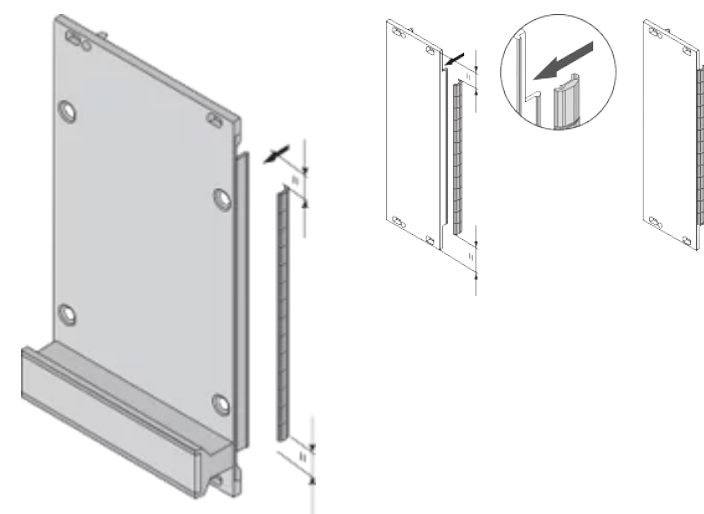

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**