


适于铁路的 EuropacPRO 19" 插箱套件，屏蔽型，EN 50155，CompactPCI，3 U，84 HP，235 mm

物料号

21500-081

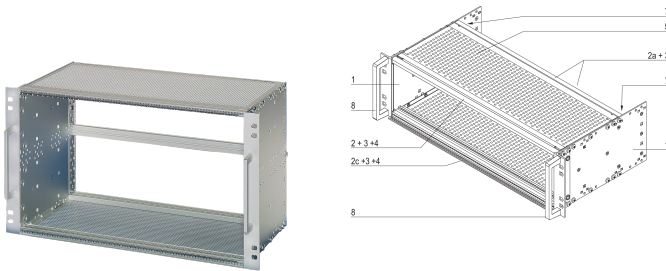

用于铁路应用的插箱，符合 EN50155 标准，适用于 Compact PCI 应用。

认证



功能

通过 EN 50155 标准的冲击和振动测试，（第 12.2.11 部分）

19" 角规牢固地固定在侧面板（TOX 冷焊），特别适合高机械应力（抗振性）

双 19" 螺钉孔位置增加了额外的安全性（NFF 标准）

IP 20，符合 IEC 60529

1 GHz 时，EMC 电磁屏蔽约为 40 dB, 2 GHz 时，约为 30 dB, 前提是正面覆盖屏蔽型前面板, 经测试符合 VG 95373 第 15 部分

铝结构

扁平包装，节省空间

产品属性

机架高度: 3U
包装数量: 1
用于安装: 背板
板深度: 160mm
垫片类型: 织物 EMC
耐冲击和振动性: 5g (force)
包含手柄: 是
安装: 机架
符合: IEC 60297-3-103; IEEE 1101.10; IEEE 1101.11; EN 50155 第 12.2.11 部分
深度: 235mm
EMC 屏蔽: 是
完成: 阳极氧化; 钝化
材料: 铝
产品类型: 插箱/机箱
机架宽度: 84HP
静态负载: 15kg
Net Weight: 2.042kg

其他产品详情

可在线获取测试报告。

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE