


Eurorack 19 英寸机柜框架，43 U 600W 600D

物料号

22117-778

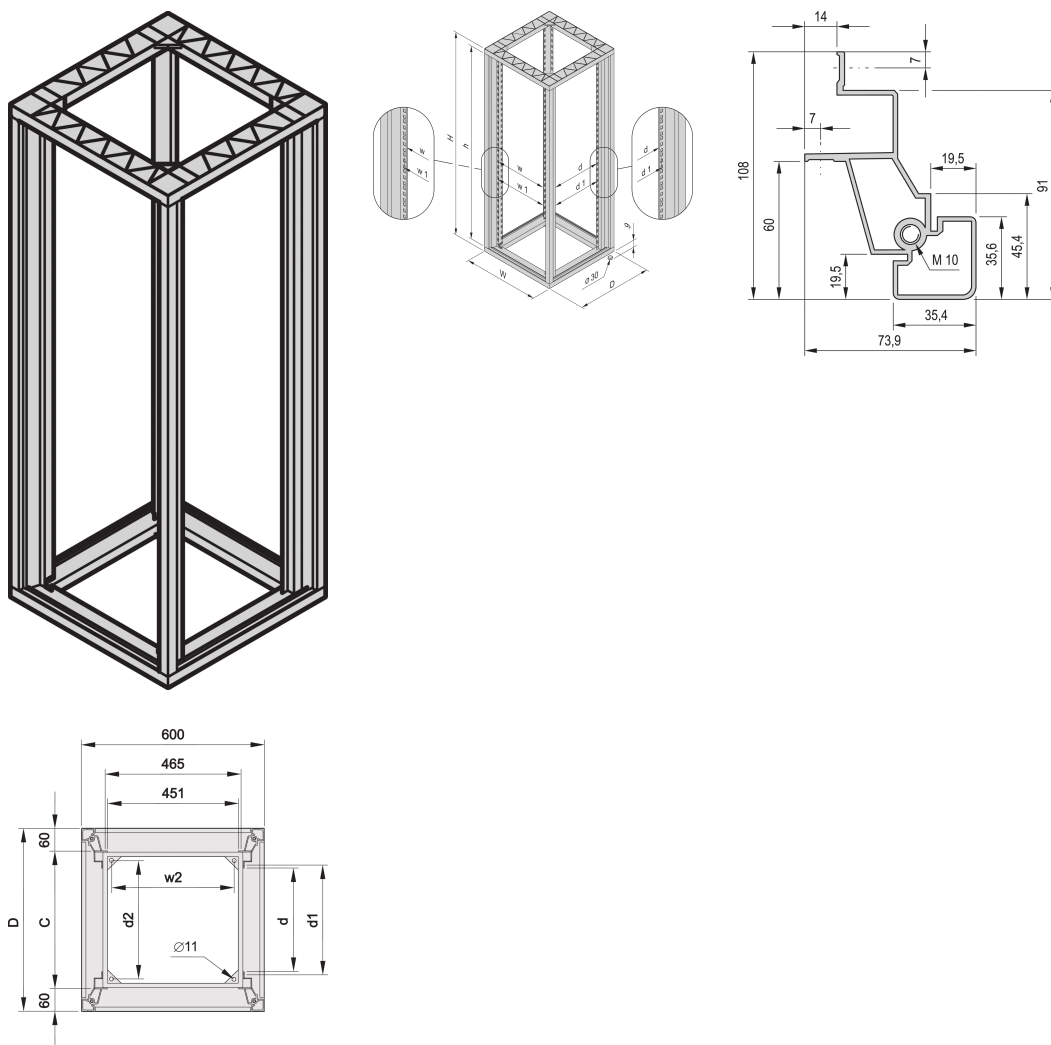

正面和背面 19" 面板之间有固定间距。

认证

功能

螺栓连接, 铝压铸框架, 立柱铝挤压件
正面和背面 19" 面板之间有固定间距
表面: RAL 7021

产品属性

产品系列: Eurorack
机架高度: 43U
高度: 2020mm
宽度: 600mm
深度: 600mm
包装数量: 1
颜色: 暗灰色
颜色代码: RAL 7021
完成: 粉末涂层
框架材料: 铝
材料: 铝
产品类型: 机柜/机架框架
静态负载: 400kg
类型: 标准
Net Weight: 35kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE