


VPX 背板, 3 U, 7 个插槽, BKP3-CEN07-15.2.3-4, RTM

物料号

23001-815

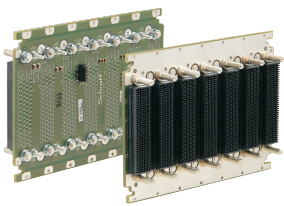

nVent SCHROFF VPX

背板拥有出色的信号完整性, 可实现最高数据传输速率。

认证



功能

符合: VITA 46.0 VPX 基本标准、VITA 46.3 Serial RapidIO on VPX、VITA 46.4 PCI Express on VPX Fabric Connector、VITA 46.7 Ethernet on VPX Fabric Connector、VITA 46.11 System Management for VPX

用于系统插槽设置的 DIP 开关

JTAG 连接

可锁定的辅助多功能连接器和传感连接器

用于电源的 M4 螺柱, 对于每个电压, 每个插槽最大 22 A

产品属性

产品类型: 背板

插槽数: 7

机架高度: 3U

背板类型: VPX, VITA 65
槽宽: 5HP
连接器类型: MultiGig
电源连接器类型: Powerstuds M4
多功能连接器类型: Microfit, 8 针
宽度: 186.46mm
Gross Weight: 0.74kg
包装数量: 1

其他产品详情

应要求提供 VPX 背板和定制 VPX 背板设计。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE