


CPCI Serial 电源背板，3 U，8 HP，1 插槽

物料号

23098-397

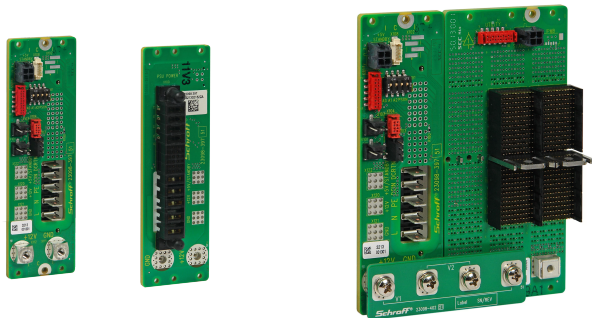

适于 CompactPCI Serial 应用的电源背板。为了提高功率或冗余，最多可以连接 4 个电源背板。

认证



功能

用于带有 FCI 电源连接器的可插拔 PSU 的电源背板

3 U, 8 HP, 1 个 PSU 连接器

用于 Fastons 的交流和直流的独立输入

12 V 型连接器, 5 V 待机, 多功能信号, current sharing, power button, 串行控制台到 UPS 和背面的数字 I/O

可选, 可安装 PICMG 2.9 SMBus 插头和用于 12 V 和 5 V 待机的电源柱

可以通过 DIP 开关设置地址

产品属性

产品类型: 背板

插槽数: 1

机架高度: 3U

背板类型: CompactPCI Serial

槽宽: 8HP

连接器类型: 01

电源连接器类型: PwrBlade

多功能连接器类型: MicroMatch, 10 针

宽度: 39.6mm

包装数量: 1

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE