


# 组合式机箱安装套件，20:62 HP

## 物料号

**24562-420**

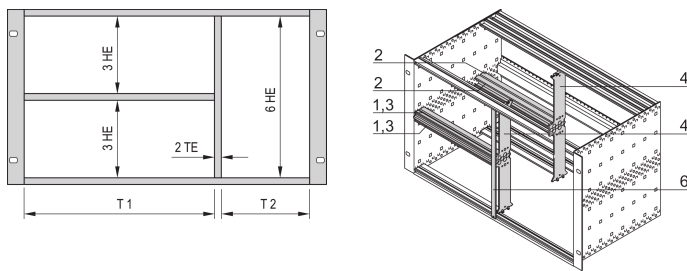

组合安装可将 6 U 高插槽或机箱拆分为 2 x 3 U 和 6 U 两部分。可提供不同版本。

## 认证



## 功能

旨在安装欧卡电路板（100 mm 高）和双高度欧卡电路板（233.35 mm 高）

6 U 装配区可拆分成：2 x 3 U, 1 x 6 U

## 产品属性

包装数量: 1

机架宽度 1: 20HP

机架宽度 2: 62HP

材料: 铝; 锌合金

产品系列: EuropacPRO

产品类型: 安装套件

机架高度: 6U

|                    |
|--------------------|
| 类型: 组合式            |
| 搭配: 插箱             |
| Net Weight: 0.45kg |

其他产品详情

Please order separately: 前面板 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE