


适用于 19" 模块支撑的 EuropacPRO 前面板，3 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

24563-096

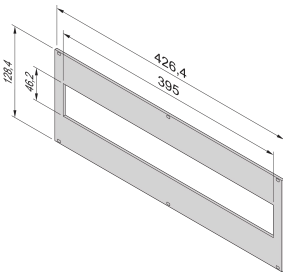

带开孔的前面板，符合 DIN 43880（适于配电模块）。

认证



功能

前面板带有符合 DIN 43880 的开孔（适用于配电模块）

高度 3 U, 宽度 84 HP

产品属性

产品类型: 前面板

产品系列: EuropacPRO

附件类型: 前面板

安装: 正面螺钉安装

材料: 铝
正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
机架高度: 3U
高度: 128.4mm
机架宽度: 84HP
宽度: 426.4mm
深度: 2.5mm
包装数量: 1
完成: 阳极氧化; 钝化
Net Weight: 0.38kg

其他产品详情

交付单中包含 2 根塑料盖板。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会导致产品故障、财产损坏、严重的个人伤害甚至死亡。请务必仔细阅读并遵守所有说明与警告。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE