


# 适合安装背板的 EuropacPRO 19 英寸插箱套件，可选装屏蔽部件，6 U，235 mm

## 物料号

**24563-432**

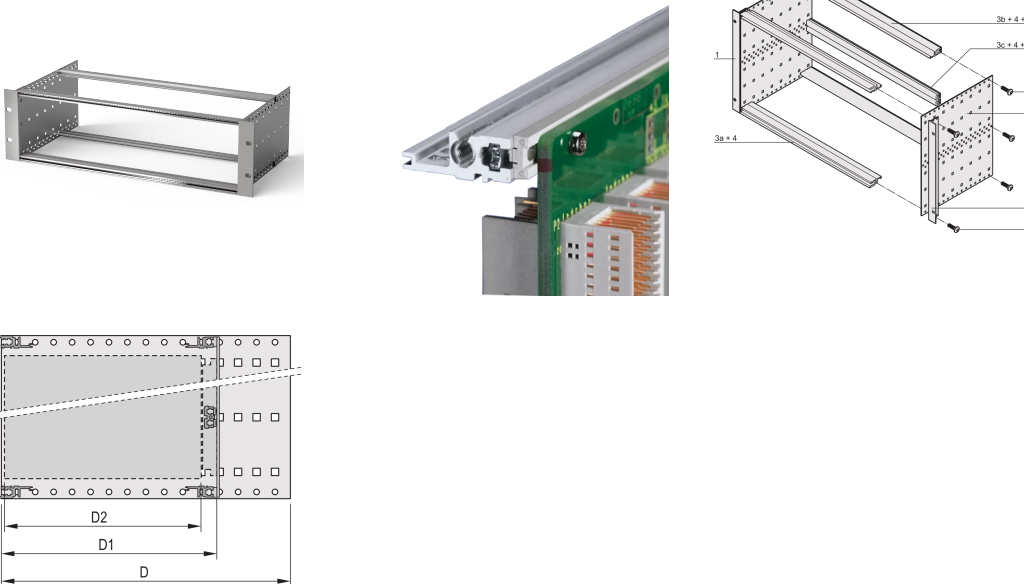

用于背板安装的非屏蔽型插箱。

## 认证



## 功能

带 F 型（“灵活型”）侧板的插箱, 包含前 19 英寸法兰, 深度可调 19" 支架单独出售（交付的产品中不随附）

用于安装背板的后水平横梁，带绝缘条

铝结构

IP 20, 符合 IEC 60529

提供改造, 如开孔、各种表面或尺寸

扁平包装, 节省空间

“轻”型水平横梁

内部和外部尺寸符合: IEC 60297-3-100, -101, IEEE 1101.1

## 产品属性

机架高度: 6U

深度: 235mm

包装数量: 1

用于安装: 背板

板深度: 160mm; 220mm

垫片类型: 不锈钢 EMC (可改装)

包含手柄: 否

安装: 机架

符合: IEC 60297-3-103

EMC 屏蔽: 否

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 插箱/机箱

机架宽度: 84HP

静态负载: 11kg

Net Weight: 1.89kg

## 其他产品详情

支持个性化配置: 支持较大范围高度, 宽度和深度定制; 根据不同应用可选多种规格导轨, 内部附件和安装材料。

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**