


# 适合安装背板的 EuropacPRO 19 英寸插箱套件，屏蔽型，6 U，415 mm

## 物料号

**24563-445**

用于背板安装的 EMC p屏蔽插箱，后侧由后面板覆盖。

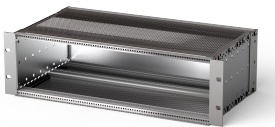

## 认证



## 功能

带 F 型（“灵活型”）侧板的插箱, 包含前 19 英寸法兰, 深度可调 19" 支架单独出售（交付的产品中不随附）

扁平包装，节省空间

提供改造，如开孔、各种表面或尺寸

1 GHz 时，EMC电磁屏蔽约为 40 dB, 2 GHz 时，约为 30 dB, 前提是正面覆盖屏蔽型前面板, 经测试符合 VG 95373 第 15 部分

IP 20，符合 IEC 60529

铝结构

内部和外部尺寸符合：IEC 60297-3-100, -101, IEEE 1101.1

用于安装背板的后水平横梁，带绝缘条

“轻”型水平横梁



## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**