


适于背板的 EuropacPRO 19 英寸插箱套件，屏蔽型，CompactPCI，6 U，275 mm

物料号

24563-457

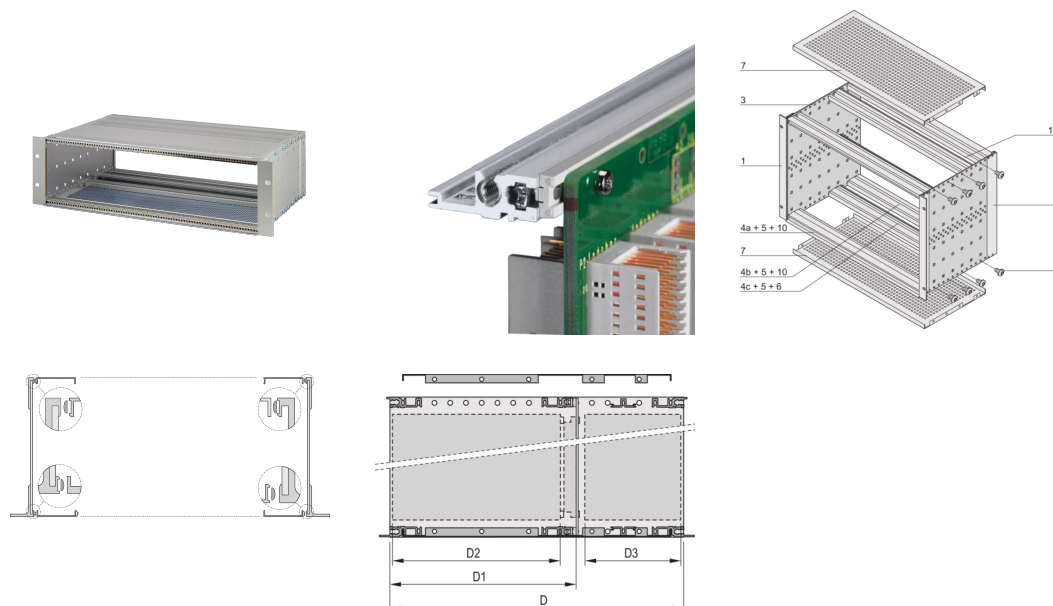

适用于背板安装的 EMC 屏蔽式插箱，适用于 CPCI 应用。

认证



功能

带 F 型（“灵活型”）侧板的插箱，适用于高插入力和抽取力的 CompactPCI 面板单元

铝结构

用于安装背板的后水平横梁，带绝缘条

内部和外部尺寸符合：IEC 60297-3-100, -101, -102, -103, -104, IEEE 1101.1, IEEE 1101.10/11

提供改造，如开孔、各种表面或尺寸

1 GHz 时，EMC电磁屏蔽约为 40 dB, 2 GHz 时，约为 30 dB, 前提是正面覆盖屏蔽型前面板, 经测试符合 VG 95373 第 15 部分

扁平包装，节省空间

IP 20，符合 IEC 60529

“重”型水平横梁

产品属性

机架高度: 6U

深度 (D): 275mm

后部 I/O: 是

包装数量: 1

用于安装: 背板

板深度: 80mm; 160mm

垫片类型: 织物 EMC

包含手柄: 否

安装: 机架

符合: IEC 60297-3-103; IEEE 1101.10; IEEE 1101.11

EMC 屏蔽: 是

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 插箱/机箱


机架宽度: 84HP

静态负载: 11kg

Net Weight: 3.42kg

其他产品详情

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

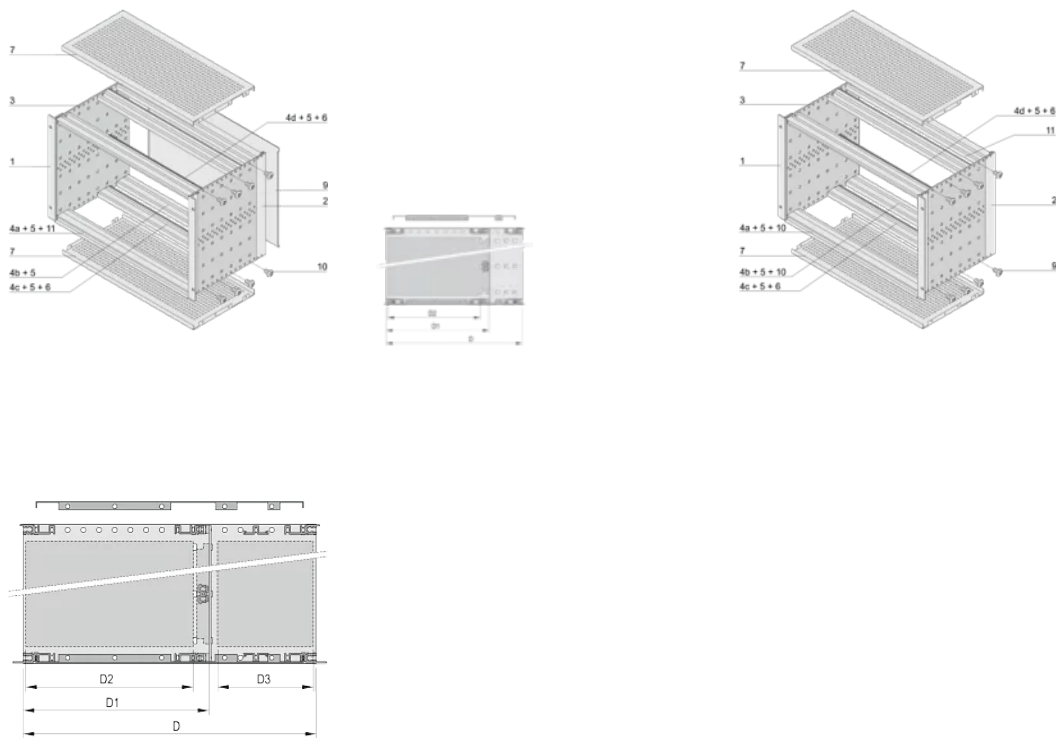

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE