
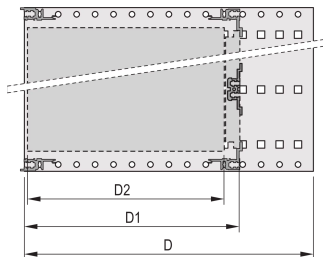
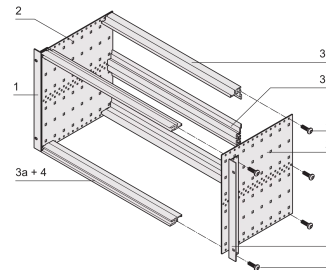


适于 DIN 连接器的 EuropacPRO 19 英寸插箱套件，改装屏蔽型，6 U，295 mm

物料号

24563-493

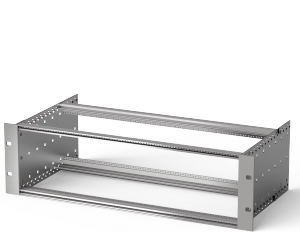

适用于 DIN 连接器安装的非屏蔽式插箱 EN 60603-2 (DIN 41612)。

认证



功能

带 F 型（“灵活型”）侧板的插箱, 包含前 19 英寸法兰, 深度可调 19" 支架单独出售（交付的产品中不随附）

铝结构

IP 20, 符合 IEC 60529

内部和外部尺寸符合：IEC 60297-3-100, -101, IEEE 1101.1

适用于连接器安装的后水平轨道 (IEC 60603-2 / DIN 41612)

提供改造，如开孔、各种表面或尺寸

扁平包装，节省空间

“轻”型水平横梁

产品属性

机架高度: 6U

深度: 295mm

包装数量: 1

用于安装: DIN 连接器

板深度: 160mm; 220mm; 280mm

垫片类型: 不锈钢 EMC （可改装）

包含手柄: 否

安装: 机架

符合: IEC 60297-3-103

EMC 屏蔽: 否

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 插箱/机箱

机架宽度: 84HP

静态负载: 11kg

Net Weight: 2.125kg

其他产品详情

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE