


适于背板的 EuropacPRO 19 英寸插箱套件，轻型，非屏蔽型，3 U，295 mm

物料号

24564-133

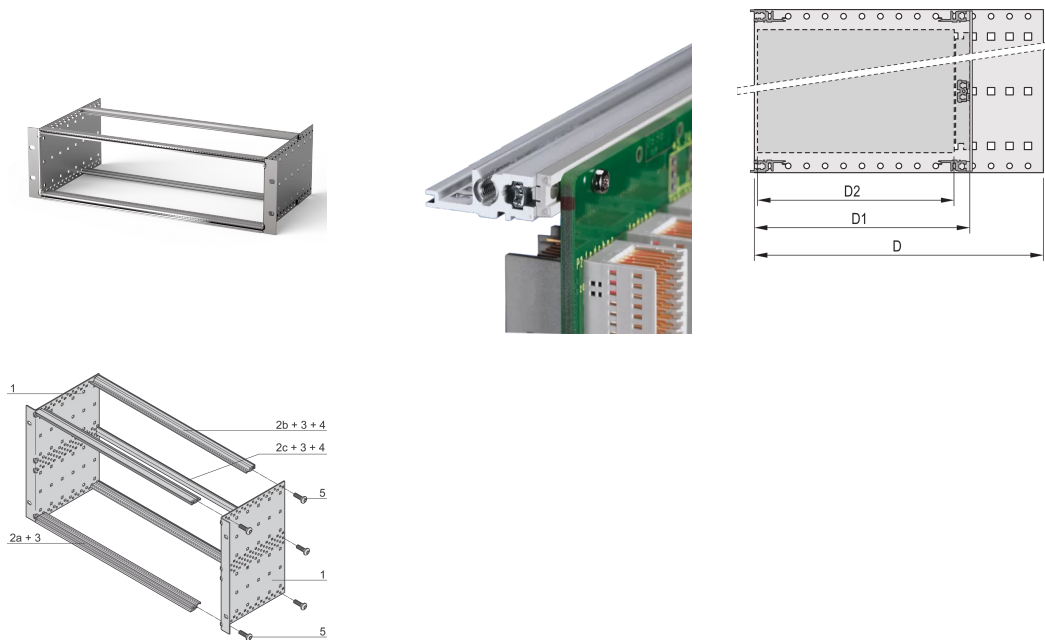

用于背板安装的非 EMC 屏蔽型插箱，轻型款。

认证



功能

插箱带有 L 型（“轻型”）侧面板，并集成 19" 支架

“轻”型水平横梁

铝结构

含用于安装背板的后水平轨道，带绝缘条

器件负载高达 7.5 千克

扁平包装，节省空间

内部和外部尺寸符合：IEC 60297-3-100, -101, IEEE 1101.1

提供改造，如开孔、各种表面或尺寸

产品属性

机架高度: 3U

深度: 295mm

包装数量: 1

用于安装: 背板

板深度: 160mm; 220mm; 280mm

包含手柄: 否

安装: 机架

符合: IEC 60297-3-100; IEC 60297-3-101; IEEE 1101.1

EMC 屏蔽: 否

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 插箱/机箱

机架宽度: 84HP

静态负载: 7.5kg

Net Weight: 1.165kg

其他产品详情

插箱没有屏蔽功能，可改装为达到 IP 20 防护等级

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE