
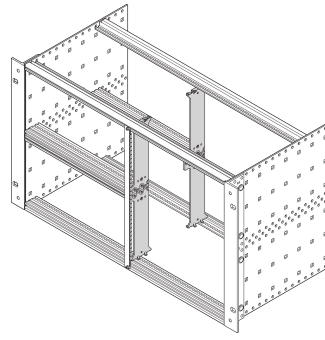


适于组合安装的拼接件，挤压成型 6 U

物料号

24566-400

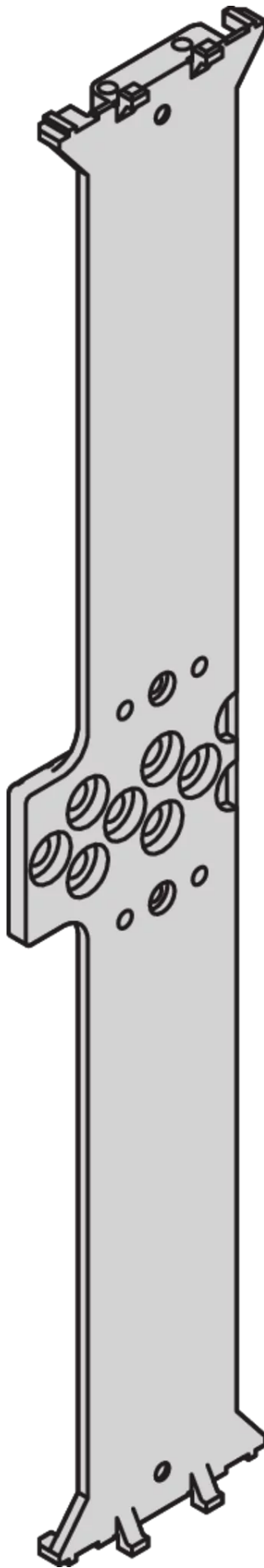

支撑装置用螺栓固定在水平横梁的网格孔中，可将 6 U 插箱拆分为 2 x 3 U 部分。

认证



功能

- 请单独订购中间水平横梁（“重型”或“轻型”）
- 拼接件用于在一个插箱中进行组合安装（方便安装6U 设备和 2 x 3U 设备）
- 正面必须用 2HP 前面板覆盖

产品属性

- 产品类型: 安装套件
- 产品系列: EuropacPRO
- 类型: 组合式，加固型
- 搭配: 插箱
- 材料: 锌合金
- 机架高度: 6U
- 包装数量: 2
- Net Weight: 0.25kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE