
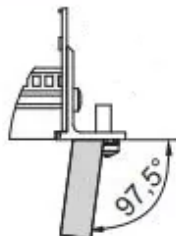
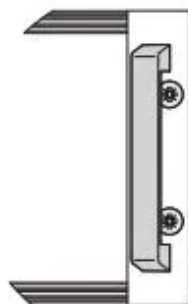
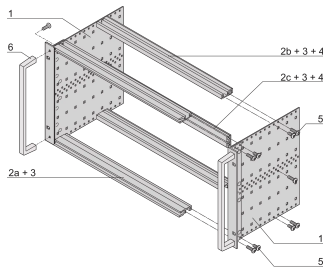
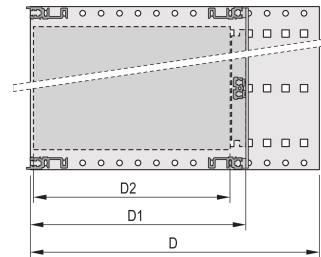


适用背板的 EuropacPRO 19 寸插箱套件，重型，改装屏蔽型，带前把手，6 U，355 mm

物料号

24567-464

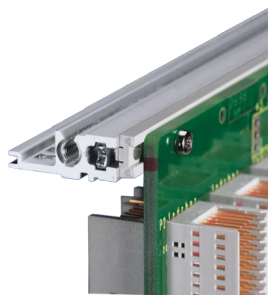

用于安装背板的非 EMC 屏蔽型插箱，重型版本带有 tox 连接侧面板和前把手。



功能

带 H 型（“重型”）侧板的插箱, 19 寸法兰固定在侧板上（TOX 冷焊）

扁平包装, 节省空间

用于安装背板的后水平横梁, 带绝缘条

“重”型水平横梁

抗冲击和振动性能高达 5 g

IP 20, 符合 IEC 60529

抗冲击和振动性能经测试符合德国 “Bahn” 标准 BN 411002, BN 411003

内部和外部尺寸符合: IEC 60297-3-100, -101, IEEE 1101.1

器件负载高达 15 千克

此版本带前把手

产品属性

机架高度: 6U

深度: 355mm

包装数量: 1

用于安装: 背板

板深度: 160mm; 220mm; 280mm; 340mm

垫片类型: 不锈钢 EMC

耐冲击和振动性: 5g (force)

包含手柄: 是

安装: 机架

符合: IEC 60297-3-103

EMC 屏蔽: 否

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 插箱/机箱

机架宽度: 84HP

静态负载: 15kg

Net Weight: 2.5kg

其他产品详情

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE