


RatiopacPRO EMC 前面板，开槽，屏蔽，3U，42 HP，2.5毫米，铝，前部经阳极氧化，后部导电

物料号

24572-604

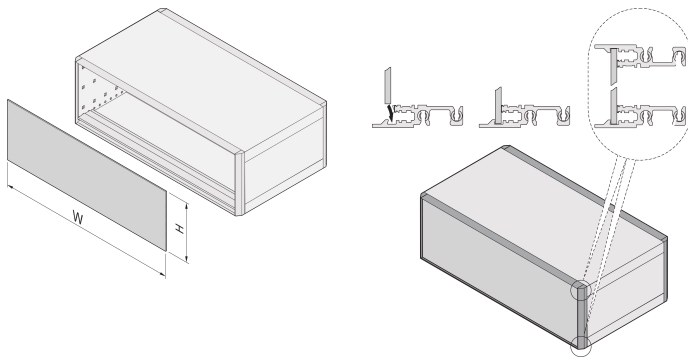

EMC 前面板可以插入具有抬高设计的特殊水平轨道中。无需螺钉即可固定。此设计可方便用户使用前面板贴膜。

认证



功能

无螺钉固定

特殊的水平轨道覆盖前面板（顶部和底部）的边缘，防止前面板弯曲

产品属性

机架高度: 3U

机架宽度: 42HP

附件类型: 前面板
包装数量: 1
正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
深度: 2.5mm
完成: 阳极氧化; 钝化
高度: 128.4mm
材料: 铝
产品类型: 前面板
宽度: 213.2mm
Net Weight: 0.55kg

其他产品详情

要获得屏蔽型机箱，必须安装所有 EMC 密封件（前面板/后面板 - 侧板）水平轨道；侧板 - 盖板；前面板/后面板 - ；水平轨道 - 水平轨道）。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客户经理索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明，可能导致人身伤害、财产损失或设备损坏。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE