


CPCI 系统，带 PSB，10 U，14 个插槽

物料号

24579-028

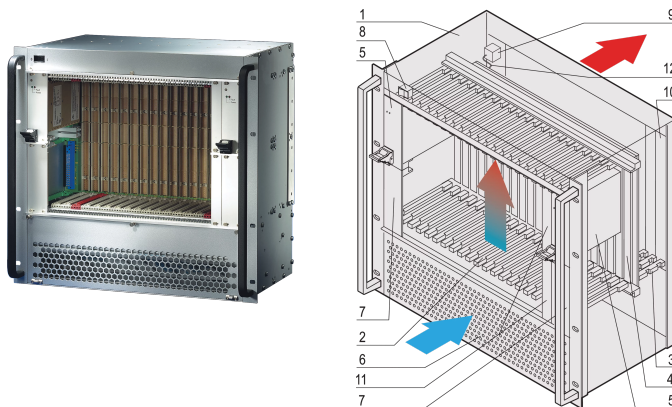

10 U CompactPCI 系统，带 PSB，适用于 14 个 6 U 板、14 个 RTM 板和最多 4 个 3U 可插拔电源。

认证



功能

系统符合 IEC 60297 - 3 - 101、- 102、- 103; IEEE 1101.1, 1101.10/11 标准; 背板, 符合 PICMG 2.16 标准

系统含垂直卡槽。前插板卡: 6 U, 160 mm 深; 后部 I/O: 6 U, 80 mm 深

背板, PSB (包交换背板), PICMG 2.16 16 槽, 6 U, 64 位 (2 个 Fabric/开关插槽, 14 个节点插槽)

风扇模块散热, 从前到后

两个 19" CompactPCI 电源, 300 W (3 U, 8 HP), 可安装两个额外的 19" 电源

可选装机箱监控模块 (CMM) 实现系统监控

产品属性

产品类型: 系统

插槽数: 16

类型: 19" 机架安装

背板类型: 6 U CompactPCI, 带 PSB

数据传输: 64 位 PCI 总线; GbE

每插槽的功率: 40W

交流输入电压: 100 – 240V

气流方向: 从前到后

机架高度: 10U

电源类型: (2) 可插拔 AC PSU

包含电源: 是

后部 I/O: 是

符合: PICMG 2.0 R3.0

深度: 275mm

高度: 443.7mm

Net Weight: 20kg

包装数量: 1

其他产品详情

可应要求提供定制系统。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE