


# CPCI 系统，带 ATX PSU，6 U，8 槽

## 物料号

**24579-030**

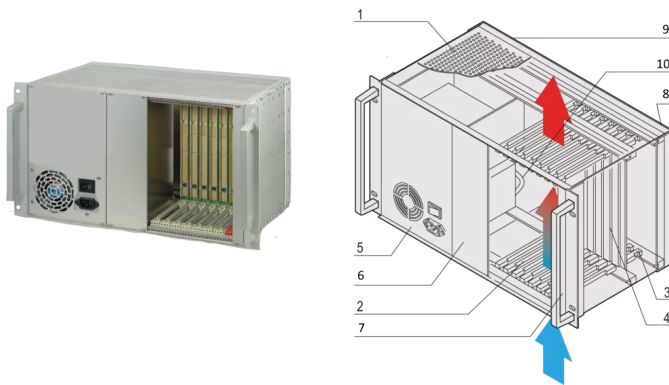

无风扇 6 U CompactPCI 系统，带垂直卡笼，适用于八个 6U 板和八个 RTM 板。带内置 ATX 电源。

## 认证



## 功能

符合 IEC 60297 - 3 - 101、- 102、- 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

系统含垂直卡槽。前插板卡：6 U, 160 mm深; 后部 I/O：6 U, 80 mm深

8 槽位背板, 6 U, 64 位, 右侧系统插槽, 可使用 8 HP 宽的 CPU

对流散热, 从下到上

可选安装5.25" DVD驱动单元

ATX PSU, 300 W

## 产品属性

产品类型: 系统

插槽数: 8

类型: 19" 机架安装

背板类型: 6 U CompactPCI

数据传输: 64 位 PCI 总线

每插槽的功率: 10W

交流输入电压: 100 – 240V

机架高度: 6U

电源类型: 1块 ATX PSU

包含电源: 是

后部 I/O: 是

符合: PICMG 2.0 R3.0

深度: 275mm

高度: 265.9mm

Net Weight: 11.76kg

包装数量: 1

## 其他产品详情

---

可应要求提供定制系统。

## 警告

---

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**