


CPCI 系统，带 ATX PSU，3 U，8 槽

物料号

24579-031

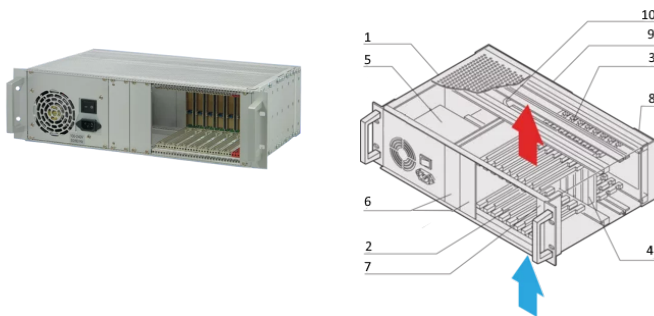

无风扇 3 U CompactPCI 系统，带垂直卡笼，适用于八个 3U 板和八个 RTM 板。带内置 ATX 电源。

认证



功能

符合 IEC 60297 - 3 - 101、- 102、- 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

系统含垂直卡槽。前插板卡：3 U, 160 mm深; 后部 I/O：3 U, 80 mm深

8 槽位背板, 3 U, 32 位; 右侧系统插槽; 可使用 8 HP 宽的 CPU

对流散热, 风道从下往上

可选安装slimline DVD驱动和硬盘

ATX PSU, 300 W

产品属性

产品类型: 系统

插槽数: 8

类型: 19" 机架安装
背板类型: 3 U CompactPCI
数据传输: 32 位 PCI 总线
每插槽的功率: 10W
交流输入电压: 100 – 240V
机架高度: 3U
电源类型: 1块 ATX PSU
包含电源: 是
后部 I/O: 是
符合: PICMG 2.0 R3.0
深度: 275mm
高度: 132.55mm
Net Weight: 8.86kg
包装数量: 1

其他产品详情

可应要求提供定制系统。

警告

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE