


适于可插拔 PSU 的 CPCI 系统，水平，2 U，4 个插槽

物料号

24579-082

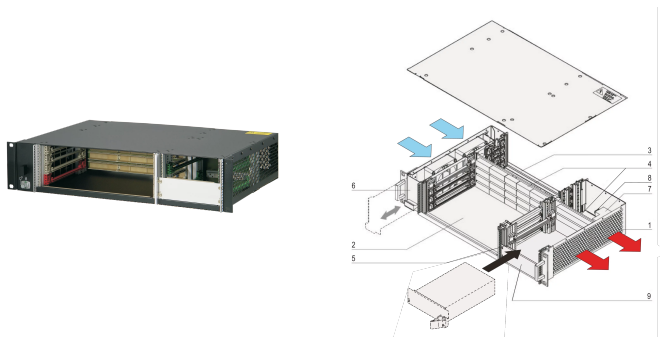

2 U CompactPCI 系统，带水平卡笼，适用于四个 6 U 板、四个 RTM 板和一个 CompactPCI 3 U 可插拔电源。可装配第二个可插拔电源。

认证



功能

符合 IEC 60297 - 3 - 101、 - 102、 - 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

带水平机笼的系统。前插板卡：6 U, 160 mm 深; 后部 I/O：6 U, 80 mm 深

e 背板（支持信号和电源的一体式背板）4 插槽, 6 U, 64 位，左侧系统插槽, 电源连接器 (2 x P 47)

通过可热插拔的风扇单元散热（气流从左往右）

可安装 19" CompactPCI 电源 (3 U, 8 HP)

产品属性

产品类型: 系统
插槽数: 4
类型: 19" 机架安装
背板类型: 6 U CompactPCI
数据传输: 64 位 PCI 总线
每插槽的功率: 40W
交流输入电压: 100 – 240V
气流方向: 从左到右
机架高度: 2U
电源类型: (1) 可插拔 PSU
包含电源: 否
后部 I/O: 是
符合: PICMG 2.0 R3.0
深度: 275mm
高度: 88.1mm
宽度: 449mm
Net Weight: 7.82kg
包装数量: 1

其他产品详情

- 可应要求提供定制系统。
- 应要求提供 48 VDC 版本。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE