


CPCI 系统，带可插拔 PSU，4 U，8 槽

物料号

24579-260

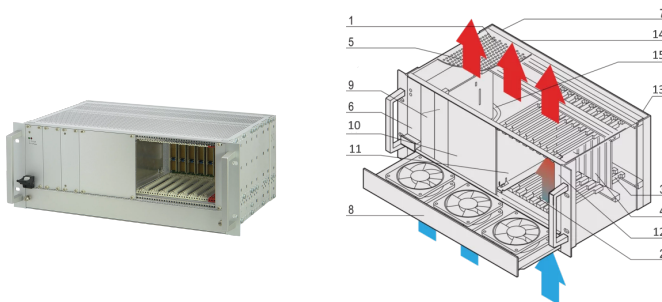

4 U CompactPCI 系统，带垂直卡笼，适用于八个 3U 板、八个 RTM 板和一个 3U 可插拔电源。

认证



功能

符合 IEC 60297 - 3 - 101、- 102、- 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

系统含垂直卡槽。前插板卡：3 U, 160 mm 深; 后部 I/O：3 U, 80 mm 深

8 槽位背板, 3 U, 32 位; 右侧系统插槽; 可使用 8 HP 宽的 CPU; 电源背板

通过 1 U 热插拔风扇单元散热, 风道从下往上

19" 兼容 PSU, 300 W, 3 U, 8 HP

可安装硬盘

产品属性

产品类型: 系统

插槽数: 8

类型: 19" 机架安装

背板类型: 3 U CompactPCI

数据传输: 32 位 PCI 总线

每插槽的功率: 40W

交流输入电压: 100 – 240V

气流方向: 从下至上

机架高度: 4U

电源类型: (1) 可插拔 PSU

包含电源: 是

后部 I/O: 是

符合: PICMG 2.0 R3.0

深度: 275mm

高度: 177mm

Net Weight: 11.23kg

包装数量: 1

其他产品详情

可应要求提供定制系统。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE