


带 ATX PSU 的 CPCI 系统。桌上型，4 U，8 槽，84 HP

物料号

24579-602

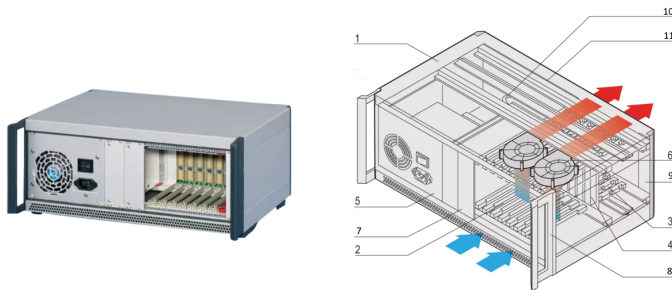

CompactPCI 桌面式机箱，带垂直卡笼，适用于8块 3 U 板、8块 3 U RTM 板和内置 ATX 电源。

认证



功能

符合 IEC 60297 - 3 - 101、 - 102、 - 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

系统含垂直卡槽。前插板卡：3 U, 160 mm深; 后部 I/O：3 U, 80 mm深

8 槽位背板, 3 U, 32 位, 右侧系统插槽; 可使用 8 HP 宽的 CPU

通过两台离心风扇散热, 气流从前向后

可选安装slimline DVD驱动和硬盘

ATX PSU, 300 W

产品属性

产品类型: 系统
插槽数: 8
类型: 桌面式
背板类型: 3 U CompactPCI
数据传输: 32 位 PCI 总线
每插槽的功率: 40W
交流输入电压: 100 – 240V
气流方向: 从前到后
机架高度: 4U
电源类型: 1块 ATX PSU
包含电源: 是
后部 I/O: 是
符合: PICMG 2.0 R3.0
深度: 275mm
高度: 177mm
Net Weight: 10.7kg
包装数量: 1

其他产品详情

可应要求提供定制系统。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE