
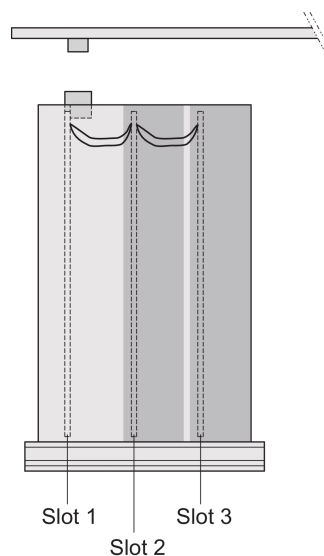
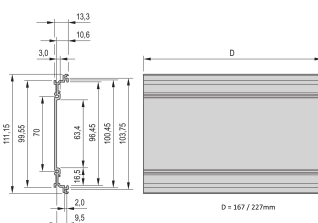
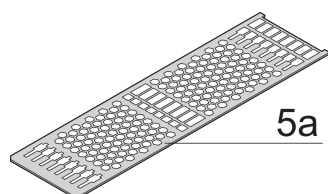
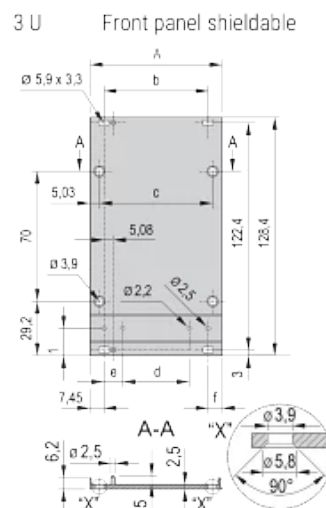


框型模件盒 PRO 套件，带孔盖，1 个连接器，3 U，21 HP，227 mm

物料号

24812-271

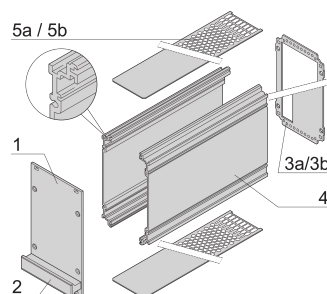

框架型插入装置，非屏蔽型，穿孔顶盖/底盖，适用于一个连接器的带开孔后面板。



功能





- 左右侧板均为挤出型材, 带有插入印刷电路板的凹槽 (标准板位置仅位于左侧)
- 后面板, 带有用于单个连接器的开孔 (符合 EN 60603, DIN 41612, 结构类型: B, C, D, F, H, Q, R, S)
- 带网孔的盖板, 用于导轨 (气流约 60%) ; 请单独订购导轨

产品属性

- 机架高度: 3U
- 机架宽度: 21HP
- 包装数量: 1
- 手柄类型: 梯形
- 后面板类型: 单连接器开孔
- 盖板类型: 穿孔盖板, 用于导轨
- 正面表面处理: 阳极氧化
- 反面表面处理: 阳极氧化
- 冷却: 穿孔
- 深度 (D): 227mm
- EMC 屏蔽: 否
- 完成: 阳极氧化
- 材料: 铝
- 产品类型: 模件盒
- 类型: 框架式插入单元 PRO
- Gross Weight: 0.772kg

其他产品详情

To fit further boards without rear connector, guide rail (part no. 24812 - 301) and 'Board fixing from slot 2' (part no. 24812 - 301 + screw part no. 24560 - 178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

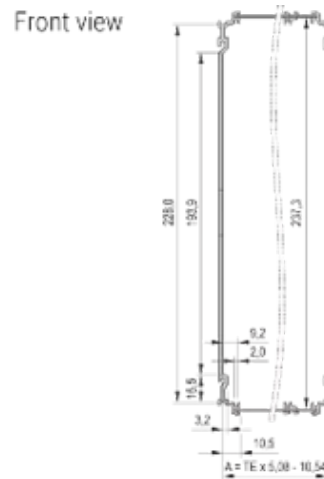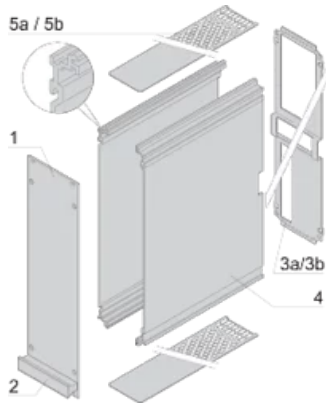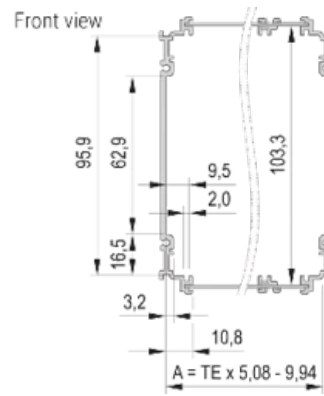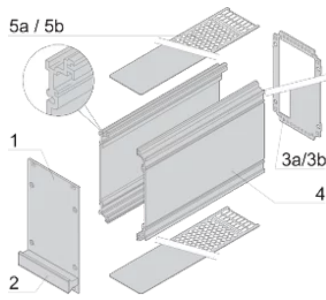

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE