


框型模件盒 PRO

套件，屏蔽型，穿孔，多连接器，3 U，14
HP，227 mm

物料号

24813-364

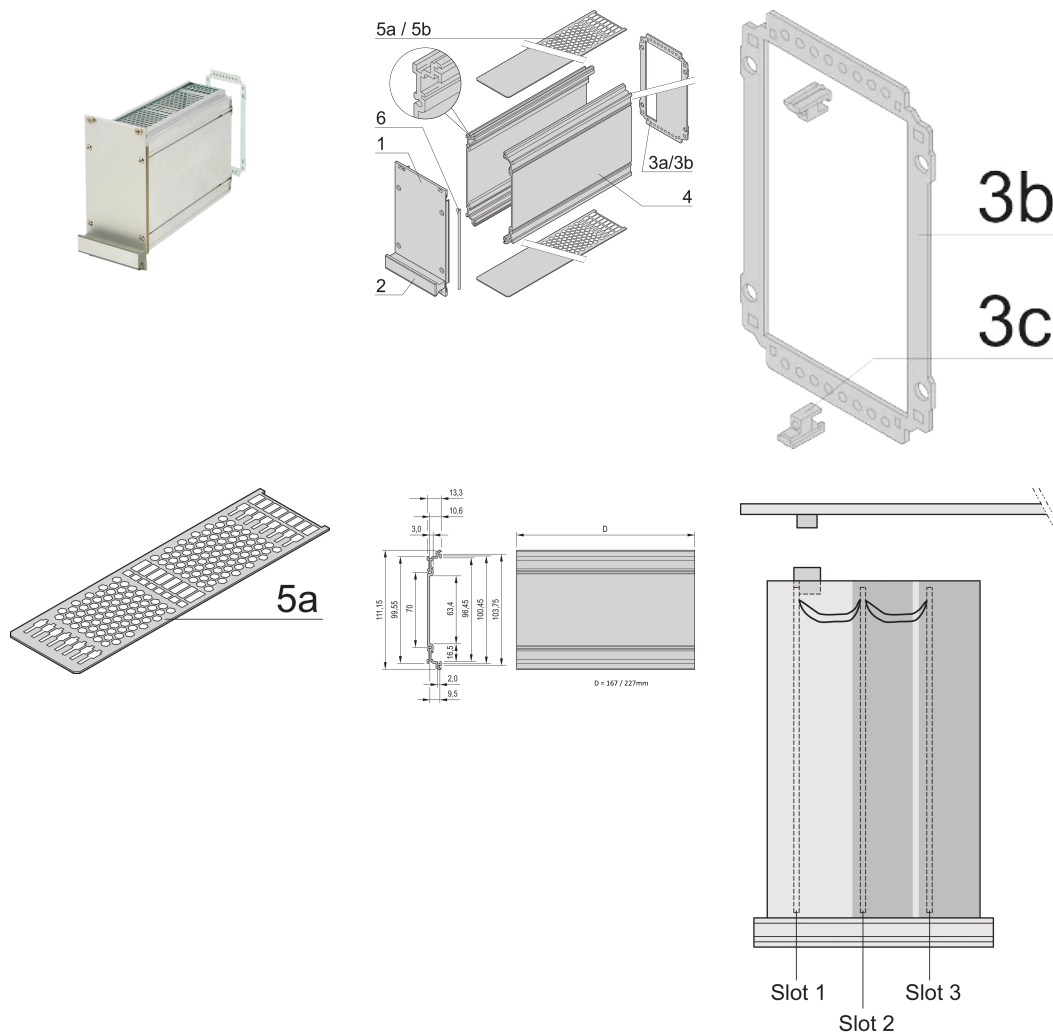

防止 PCB 遭受机械损坏和静电积聚；适用于欧洲板规格；与带多个连接器开孔的面板搭配。



功能

- 带网孔的盖板, 弹簧承载装置 (气流约 60%)
- 后面板, 带有可装多个连接器的开孔
- 挤出侧板, 右侧和左侧有凹槽, 可插入 PCB (板卡的位置距离左侧板距离符合标准)

产品属性


- 机架高度: 3U
- 机架宽度: 14HP
- 包装数量: 1
- 手柄类型: 梯形
- EMC 垫片类型: 织物
- 后面板类型: 多个连接器开孔
- 盖板类型: 穿孔盖板, 用于导轨
- 正面表面处理: 阳极氧化
- 反面表面处理: 阳极氧化
- 冷却: 穿孔
- 深度 (D): 227mm
- EMC 屏蔽: 是
- 完成: 阳极氧化; 钝化
- 材料: 铝
- 产品类型: 模件盒
- 类型: 框架式插入单元 PRO

其他产品详情

请单独订购导轨。

To fit further boards without rear connector, guide rail (part no. 24812 - 301) and 'Board fixing from slot 2' (part no. 24812 - 301 + screw part no. 24560 - 178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and

one slot 2 are already included.

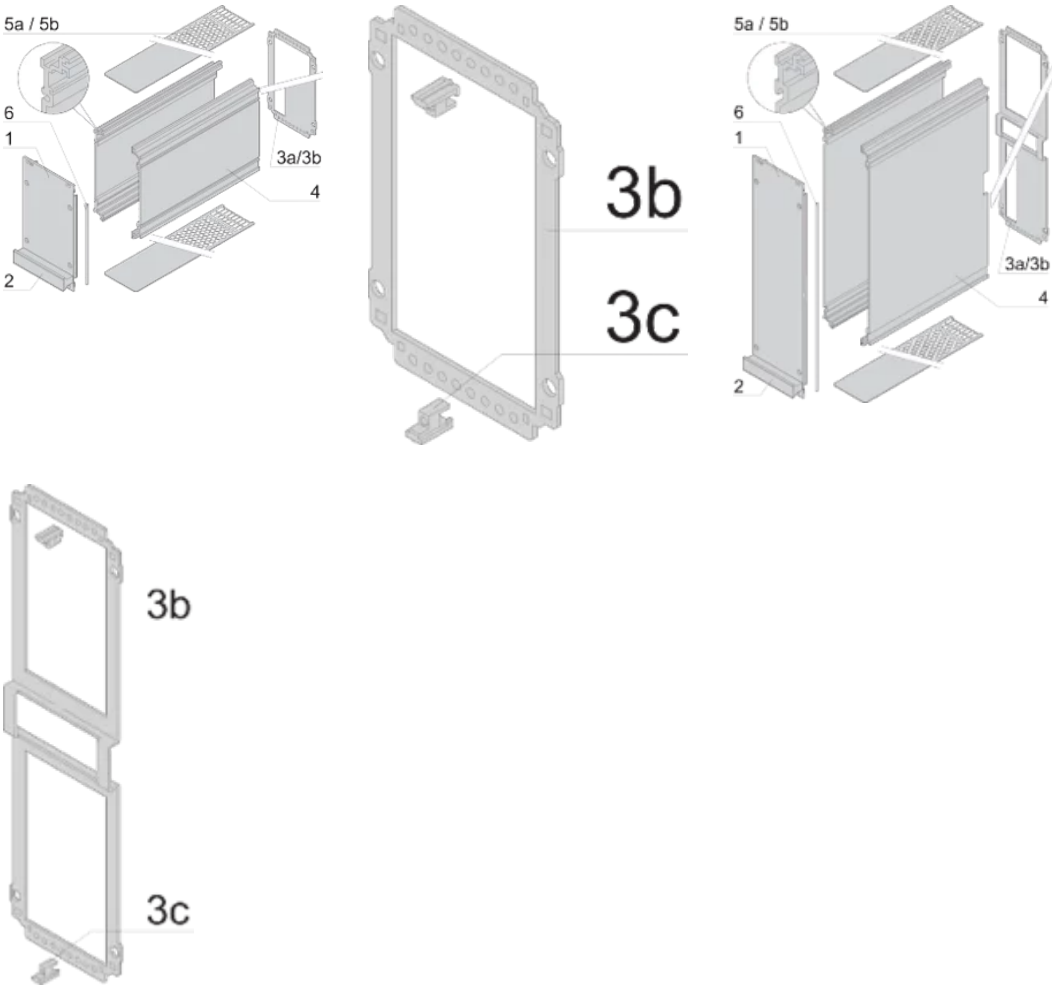

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE