


# Minipac 梯形机箱，壁挂式

## 物料号

**24814-010**

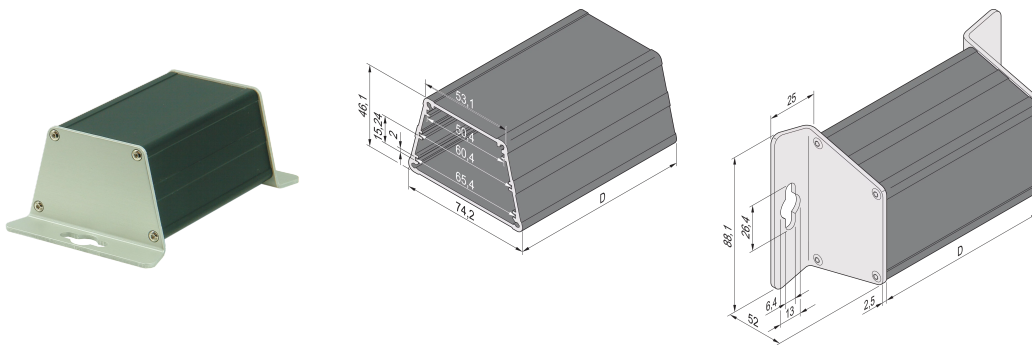

梯形铝型材机箱有助于用户插入 3 个非标准 PCB。PCB 安装到铝型材凹槽中。双侧由用于壁挂的 2.5mm L 形前面板覆盖。

## 认证



## 功能

壁挂式安装

PCB 厚度 1.6 mm, 间距 15.24 mm (3 HP)

长度 D = 100 mm, 长侧宽度 74.2 mm, 短侧宽度 54.5 mm, 高度 46.1 mm

安放 3 个非标准化 PCB (高度 50, 60 和 65 mm, 深度 100)

## 产品属性

产品类型: 小尺寸机箱

产品系列: Minipac

类型: 壁挂式安装

高度: 88.1mm

|                    |
|--------------------|
| 宽度: 52mm           |
| 深度: 100.5mm        |
| 材料: 铝              |
| 颜色: 黑色             |
| 完成: 阳极氧化           |
| 防护等级: IP40         |
| 冷却: 非穿孔            |
| 形状: 梯形             |
| 包装数量: 1            |
| 长度: 100.5mm        |
| Net Weight: 0.27kg |

### 其他产品详情

应要求提供其他尺寸。

### 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE