


IP-PRO 铝制机箱，EMC，110H 600W 310D，IP67

物料号

26880-014

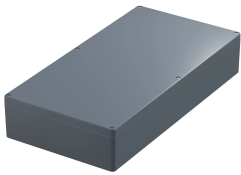

IP-Pro ALU EMC -

能够可靠地屏蔽水、灰尘和电磁干扰的机箱，适合在严苛环境中保护敏感的电子部件。通过相关认证，适用要求高冲击和振动要求的应用。

功能

铝压铸机箱，可提供 15 种不同尺寸，带有银灰色户外粉末涂层 (RAL 7001)

视尺寸而定，符合 EN 60529 标准的 IP67 等级防护

EMC 屏蔽

符合 EN 61373 Cat. 2 和 AREMA Class I 的耐冲击和抗振性能

符合 IEC 62262 标准的 IK 09 等级防护，抵御外部机械影响

机箱的适用温度范围 -40 至 +90°C

产品属性

高度: 110mm

宽度: 600mm

深度: 310mm

防护等级: IP67

包装数量: 1

颜色: 银灰色

颜色代码: RAL 7001

完成: 粉末涂层
材料: 铝
产品系列: IP-PRO ALU EMC
产品类型: 小尺寸机箱
形状: 矩形
类型: 加固型
Net Weight: 8.6kg

其他产品详情

有关机械改造、创新的 PCB 和电缆固定解决方案以及冷却概念的信息，请联系我们。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE