


Eurorack 滑轨，40 千克，深度可调

物料号

28127-001

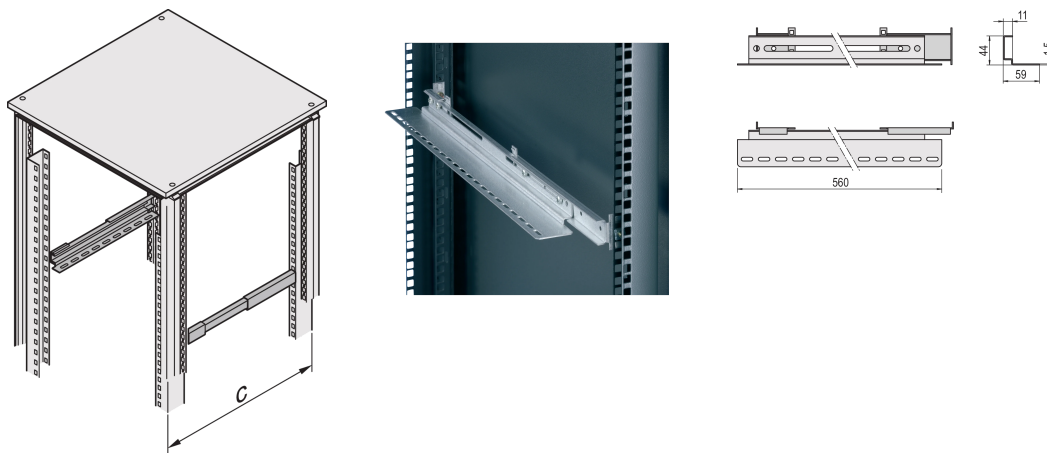

Eurorack L型滑动安装轨，承载能力为 40 kg，适合安装在机柜立柱或 19" 面板/角轨安装件上。滑轨可以支撑重型 19" 机箱的机架。

认证



功能

可按 1 U 增量安装

静态承载能力 40 千克/每对, 深度可调

碳钢, 1.5 mm, 覆铝锌表面

适用于安装到 19" 面板/滑轨安装件或 19" 服务器面板/滑轨安装件（间距 c 从 675 mm至 850 mm）

重型 19" 模块支架

宽支撑表面

产品属性

产品类型: 滑轨
产品系列: Eurorack
材料: 钢
完成: 镀锌铝
长度: 560mm
静态负载: 40kg
包装数量: 1
Gross Weight: 2.26kg

其他产品详情

仅适用于从 800 mm 深度安装机架。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE