


HF 框架型模件盒主体, 14 HP, 用于 160 mm 深 PCB

物料号

30809-673

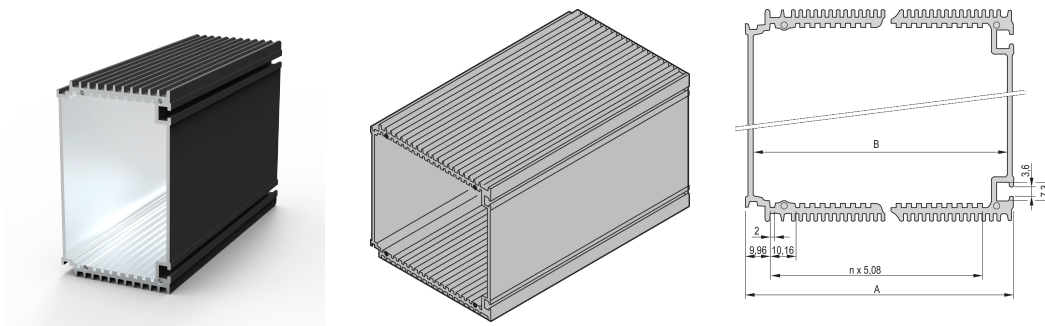

黑色 HF 主体构件, 适用 HF 模件盒, 帮助安装 PCB。

认证



功能

黑色 HF 主体构件, 适用于 HF 模件盒, 帮助安装 PCB

此构件可屏蔽高频率辐射

带散热片的模块

模件盒可以安装在插箱中, 或用滑动螺母横向安装在安装板上

产品属性

机架宽度: 14HP

包装数量: 1

完成: 阳极氧化

长度 (L): 167mm

材料: 铝

产品类型: 盖板

机架高度: 3U

搭配: 模件盒

Gross Weight: 0.447kg


PCB 长度 (公制) : 160mm

其他产品详情

请单独订购前面板、后面板、PCB 支架和固定材料。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

图

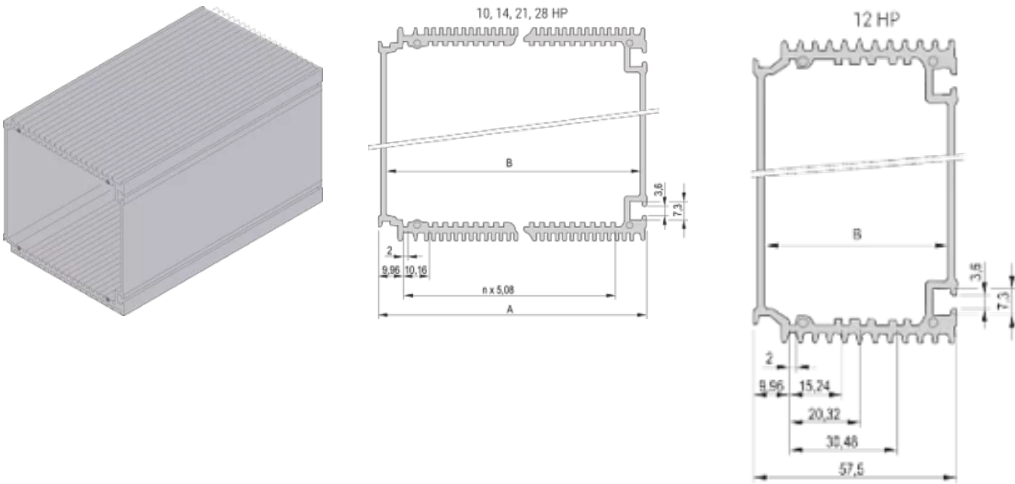

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE