


# 前面板，未屏蔽，6 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

## 物料号

**30838-204**

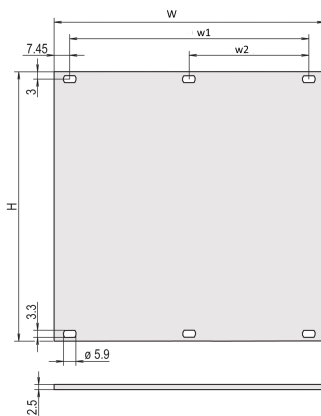

前面板，未屏蔽，前部经过阳极氧化，后部导电。

## 认证



## 功能

非全宽前面板, 铝, 2.5 mm

铝, 正面阳极氧化, 导电

## 产品属性

机架高度: 6U

包装数量: 1

附件类型: 前面板

安装: 正面螺钉安装

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: IEC 60297-3-101; IEEE 1101.1/10

深度 (D): 2.5mm

EMC 屏蔽: 否

完成: 阳极氧化; 钝化

高度 (H): 261.8mm

材料: 铝

产品类型: 前面板

类型: 不带把手的前面板


宽度 (W): 426.4mm

Net Weight: 0.7kg

其他产品详情

请单独订购紧固零件（螺钉套，凸缘螺钉）。

图

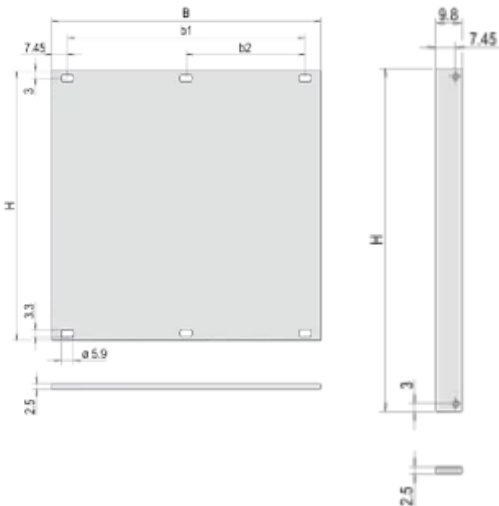

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**