

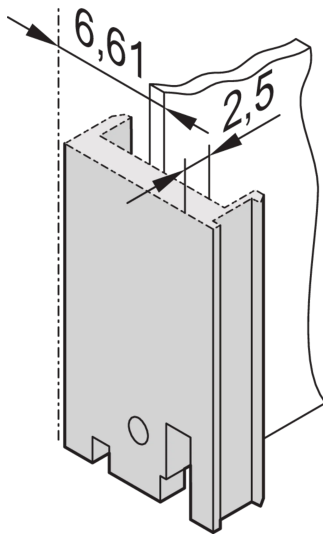
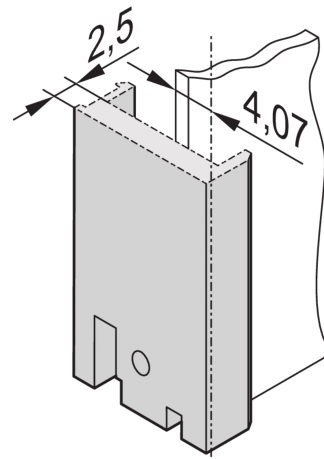


适用于 IEL 的插入式装置 U 型前面板，IET，2
型把手，6 U，4 HP，2.5
毫米，铝，前部经阳极氧化，后部导电

物料号

30848-317

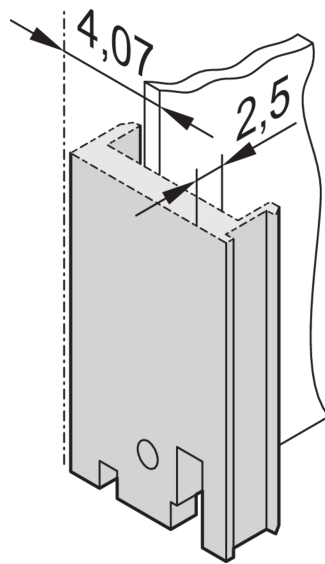

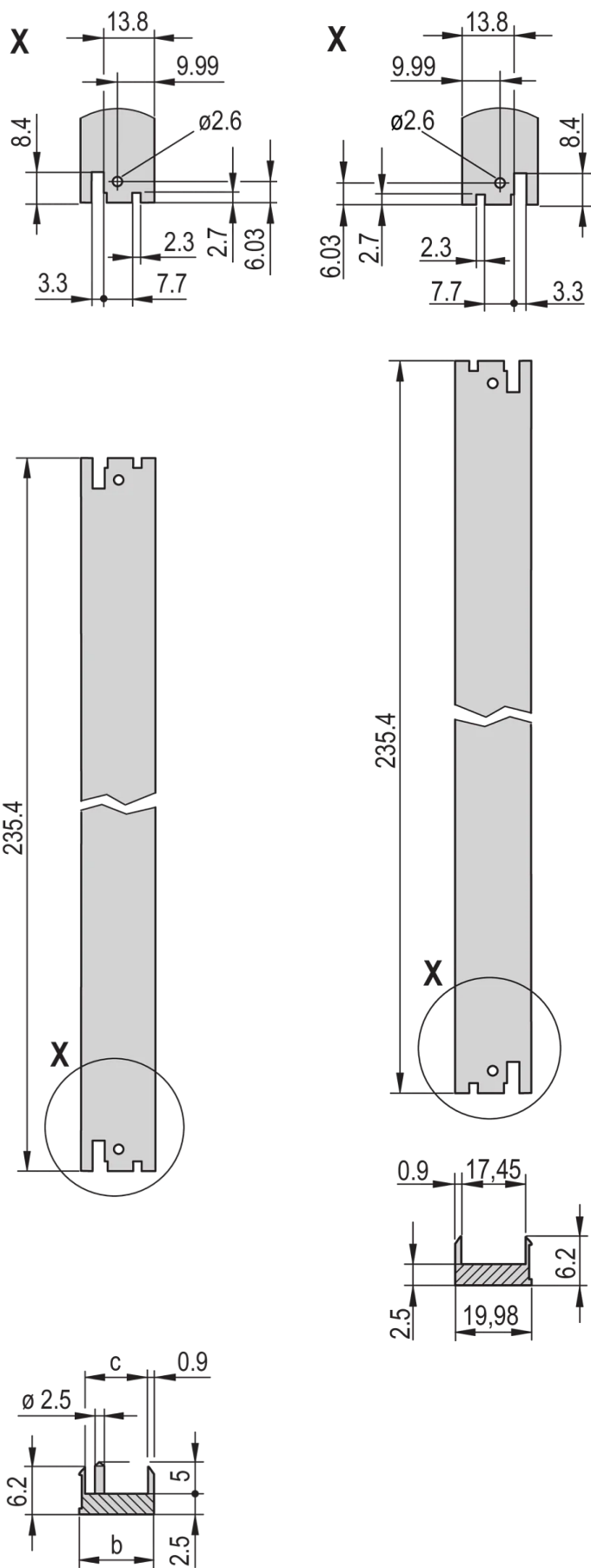

U 型材前面板可以用织物屏蔽条屏蔽。它可以与 IEL 和 IET 或类型 2 梯形把手结合使用。



功能

前面板, 6 U

铝挤压件, 2.5 mm, 正面阳极氧化, 背面导电

U 型, 带 EMC 泡棉垫片, 具有屏蔽功能

适用于 IEL/IET/梯形类型 2 把手

制造工艺导致各种表面架构的间距为 4 至 12 HP 和 14 至 16 HP

用于正面安装, 具有 0.1" 偏移的 PCB 固定件

用于背面 I/O 安装

产品属性

机架宽度: 4HP

包装数量: 1

附件类型: 前面板

手柄类型: IEL; IET; 梯形, 类型 2

安装: 正面螺钉安装; 背面螺钉安装 IO

EMC 垫片类型: 织物

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11

深度 (D): 2.5mm

EMC 屏蔽: 无 (可改装)

完成: 阳极氧化; 钝化

高度 (H): 261.8mm

材料: 铝

产品类型: 前面板

机架高度: 6U

类型: 把手前面板 (PIU)


宽度 (W): 20mm

其他产品详情

请单独订购 EMC 型材屏蔽材料。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

图

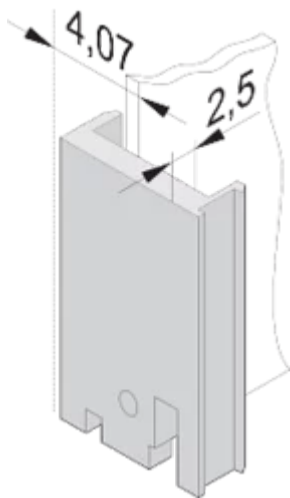

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE