


适用组合安装的前面板替代产品，U 型，泡棉，6 U，2 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

30849-140

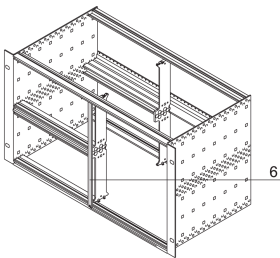

2 HP 宽的前面板可以覆盖开口插槽。U 形前面板可与泡棉 EMC 垫片结合使用。可用螺钉和垫圈固定。由于宽度为 2 HP，因此不能使用螺丝套。

认证



功能

U 形前面板 6 U, 2 HP, 铝, 2.5 mm

适用于泡棉 EMC 垫片

产品属性

产品类型: 前面板

附件类型: 前面板

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

安装: 正面螺钉安装

EMC 屏蔽: 无 (可改装)

EMC 垫片类型: Textile

材料: 铝

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

机架高度: 6U

高度: 261.8mm

机架宽度: 2HP

宽度: 9.8mm

深度: 2.5mm

符合: IEC 60297-3-101; IEEE 1101.1/10

包装数量: 1

完成: 阳极氧化; 钝化

Net Weight: 0.021kg

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE