


水平轨道，前端，L-OD 型，轻型，不带长舌，42 HP

物料号

34560-042

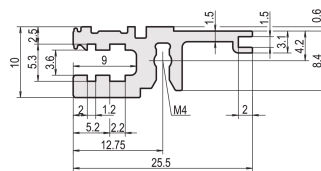

Combinations of horizontal rails and side panels

„+“ = can be combined, „-“ = combination not recommended

	Horizontal rail	Horizontal rail with side panel	Horizontal rail with side panel (for 28 HP)	Horizontal rail with side panel (for 28 HP)
Horizontal rail	-	+	+	+
Horizontal rail with side panel	+	+	+	+
Horizontal rail with side panel (for 28 HP)	+	+	+	+
Horizontal rail with side panel (for 28 HP)	+	+	+	+
Horizontal rail	+	+	+	+
Horizontal rail with side panel	+	+	+	+
Horizontal rail with side panel (for 28 HP)	+	+	+	+
Horizontal rail with side panel (for 28 HP)	+	+	+	+

Side panel

Light 1.1

Standard 1.1

Heavy 1.1

Super 1.1

不带长舌的水平横梁可将 6 U 前面板等元素安装到拆分成 2 x 3 U 配置的插槽。

认证



功能

适合安装在全宽前面板后

< 28 HP 无丝印

不带长舌 (L-OD)

铝挤压件, 阳极氧化, 接触表面导电

产品属性

机架宽度: 42HP

包装数量: 1

完成: 阳极氧化

长度: 218.44mm

材料: 铝

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

产品类型: 水平横梁

类型: 轻型, OD

搭配: 插箱; 仪器箱

Net Weight: 0.067kg

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE