
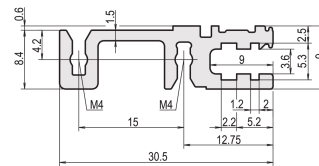


H-VT 型水平轨道，后部，重型，84 HP

物料号

34560-784

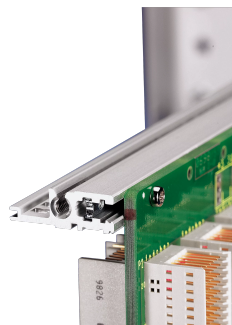

Combinations of horizontal rails and side panels

		+ = can be combined, - = combination not recommended			
Horizontal rail	Standard 1.0	-	+	+	+
	Standard 1.5	+	+	+	+
	Standard 2.0	+	+	-	-
Side panel	Light 1.0	+	+	-	-
	Standard 1.0	+	+	-	-
	Standard 1.5	+	+	-	-
	Standard 2.0	+	+	-	-

VT 型横梁，可直接装配背板。

认证



功能

用于直接安装背板

安装在插槽顶部和底部

嵌入式安装，适用于较高机械振动环境 (H-VT)

铝挤压件, 阳极氧化, 接触表面导电

产品属性

机架宽度: 84HP
宽度: 431.8mm
包装数量: 1
深度: 30.5mm
完成: 阳极氧化
高度: 9mm
长度: 431.8mm
材料: 铝
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: 水平横梁
类型: 重型, VT
搭配: 插箱; 仪器箱
Gross Weight: 0.149kg

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE