


前面板，全宽，开槽，非屏蔽，适用于 RatiopacPRO 4 U，AIR 5 U，84 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

34571-612

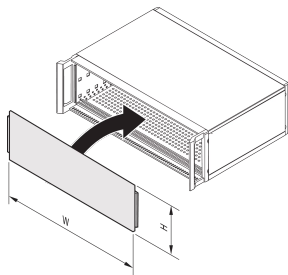

全宽，带插槽，非屏蔽型前面板，适用于 RatiopacPRO/-AIR。

认证



功能

插入侧板和压铸部件之间，例如饰件，19" 安装支架或把手

前面板也可用作后面板

无螺钉固定（特殊水平轨道覆盖前面板的边缘，并将其保持到位

屏蔽（后导电）；如需与机箱导电连接，请单独订购 EMC 密封（不锈钢）

产品属性

机架高度: 4U

机架宽度: 84HP

包装数量: 1

附件类型: 前面板

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

深度 (D): 2.5mm

完成: 阳极氧化; 钝化


高度 (H): 172.9mm

材料: 铝

产品类型: 前面板

宽度 (W): 426.4mm

Net Weight: 0.5kg

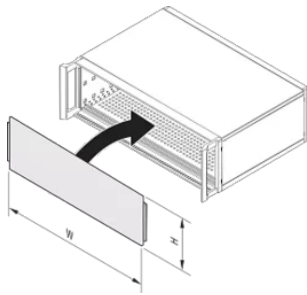

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE