


适用于后部 I/O 的 AB 型后水平横梁，带槽口，84 HP

物料号

34579-040

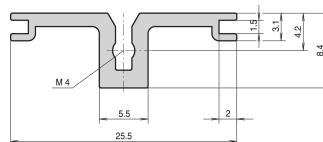

Combinations of horizontal rails and side panels

“+” = can be combined, “-” = combination not recommended

	Standard 1.0	Standard 1.5	Standard 2.0	Standard 2.5
Standard 1.0	-	+	+	+
Standard 1.5	+	+	+	+
Standard 2.0	+	+	+	+
Standard 2.5	+	+	+	+
Side panel	Light 1.0	Standard 1.0	Heavy 1.0	Rugged 1.0

Side panel: Light 1.0, Standard 1.0, Heavy 1.0, Rugged 1.0

AB型铝挤出水平轨道(AB=支撑)用于后I/O导轨，具有阳极氧化处理的表面以及接触面导电性能。适用于 RatiopacPRO/-AIR 和 EuropacPRO/-rugged) 。

功能

适用含后部 I/O 的 CompactPCI

适用 2×3 U 扩展, 需要 AB 型 2 水平轨道

铝挤压件, 阳极氧化, 接触表面导电, 未带HP标识

产品属性

机架宽度: 84HP

包装数量: 1

完成: 阳极氧化

长度: 431.8mm

材料: 铝

产品系列: EuropacPRO

产品类型: 水平横梁

类型: AB 型
搭配: 插箱
Net Weight: 0.073kg
轨道类型: 带有卡槽

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE