


框架型插入装置前面板，改进屏蔽型，3 U，8 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

34813-108

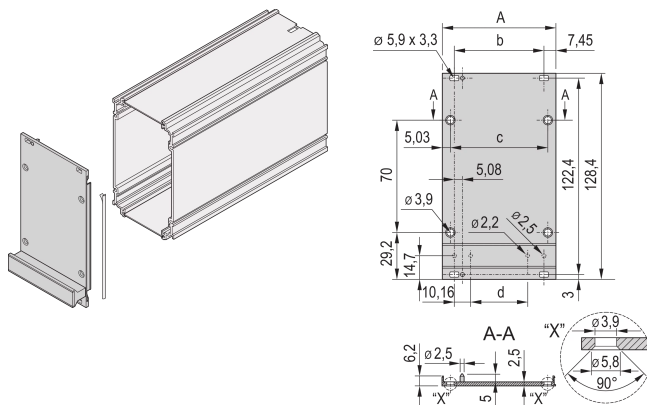

适用于模件盒的前面板，屏蔽型。

认证



功能

适用于模件盒的前面板，可定制该面板

铝挤压件，定位销压入，正面阳极氧化，背面导电

产品属性

机架高度: 3U

附件类型: 前面板

机架宽度: 8HP

包装数量: 1

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

深度 (D): 2.5mm

完成: 阳极氧化

高度 (H): 128.4mm

材料: 铝


产品类型: 前面板

宽度 (W): 40.3mm



其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。


用于将前面板固定到模件盒的安装套件、用螺栓固定的把手、用于将模件盒安装到插箱或机箱中的塑料套和螺钉均包含在“五个面板套件的安装套件”项目中，部件号 24812 - 100。

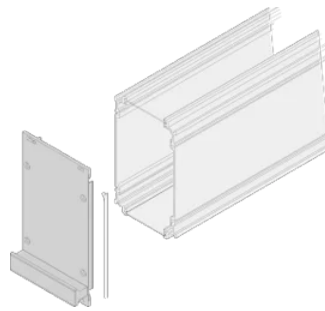


3 U Front panel shieldable

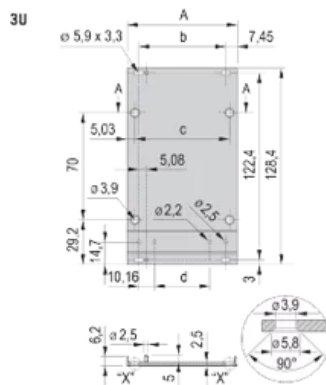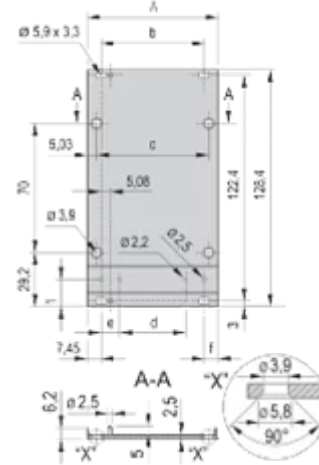

6 U

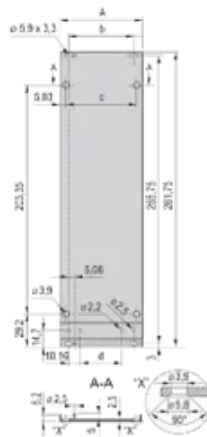

6 U Front panel shieldable

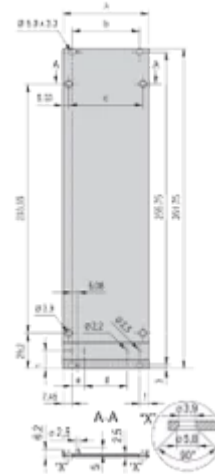

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE