


框架型插入装置挤压侧面板，螺钉固定版本，3 U，D = 227 mm，对称

物料号

34813-300

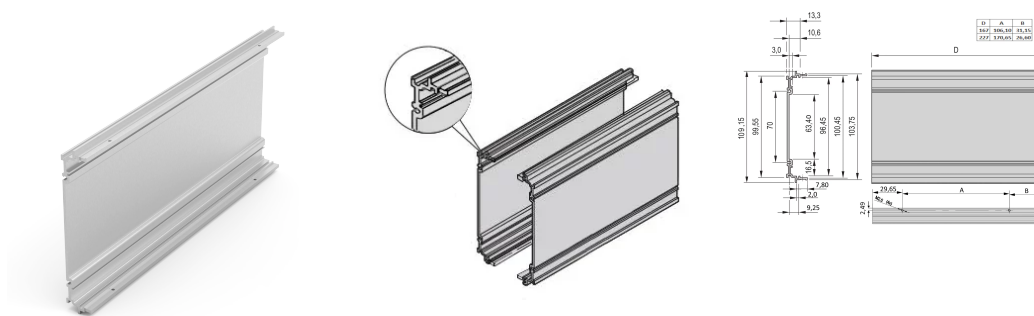

适用于框架型插入装置的侧面板。

功能

集成的侧向凹槽，以装配 PCB

用于构建插入装置的侧面板包含铝挤压件

顶盖/底盖可用螺钉固定

产品属性

包装数量: 1

PCB 长度（公制）: 227mm

完成: 钝化

高度 (H): 111.15mm

长度 (L): 220mm

材料: 铝

产品类型: 侧面板

机架高度: 3U

类型: screw-fixed


宽度 (W): 178mm

搭配: 框架式插入单元

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

图

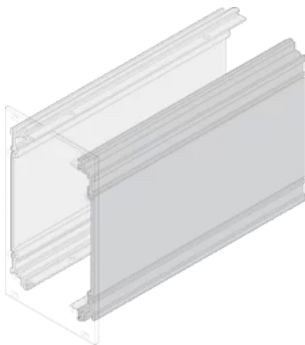

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会导致人员伤亡、财产损失、严重的个人伤害和/或身体残疾及财产损失。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE