


19" 前面板, 7 U, 4 毫米, 铝, 阳极氧化

物料号

40304-080

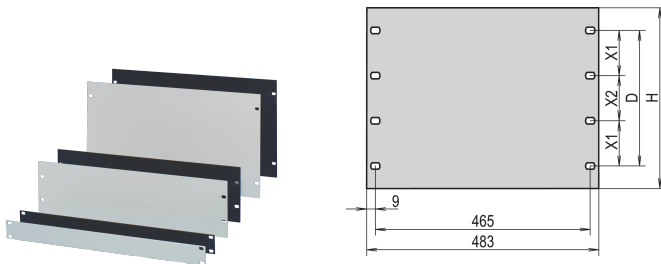

前面板为阳极氧化铝材质.

认证



功能

铝, 厚度 4 或 3 毫米, 阳极氧化或涂漆

产品属性

机架高度: 7U

深度 (D): 4mm

附件类型: 前面板

安装: 正面螺钉安装

完成: 阳极氧化

正面表面处理: 阳极氧化

包装数量: 1

反面表面处理: 阳极氧化

边缘处理: 是

EMC 屏蔽: 否

高度 (H): 310.3mm

材料: 铝

产品类型: 前面板

机架宽度: 95HP

类型: 19" 前面板


宽度 (W): 483mm

Net Weight: 1.58kg

其他产品详情

请单独订购 19" 装配套件。

图

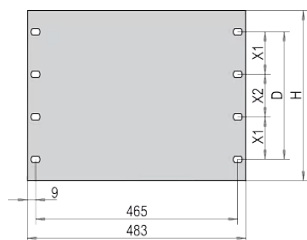

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE