


# UTE 插座条，3 相，9 个插座

## 物料号

**60110-233**

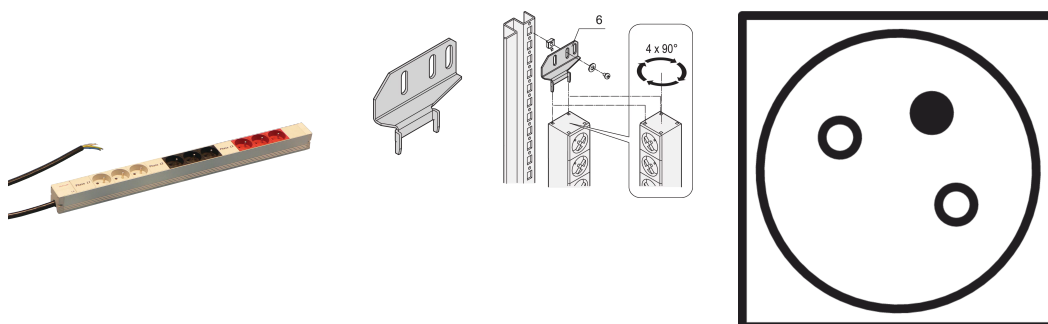

模块化、紧凑型 PDU，支持多种功能。PDU 采用 1 U x 1 U 铝机箱，可轻松集成在带 UTE 插座的机架中。

## 认证



## 功能

连接电缆 2 米, 开放端带套管

安装时，插排可以向四个方向旋转（90°增量）

带 UTE 插座的插排, 3 相

3 相, 每相 16 A

符合 NFC 61-303 标准

垂直安装

安装高度 1 U

## 产品属性

产品类型: 插排

|                |
|----------------|
| 插座类型: UTE      |
| 插座数量: 9        |
| 颜色: 灰色; 黑色; 红色 |
| 开关插座: 否        |
| 长度: 608.5mm    |
| 交流电压: 230V     |
| 深度: 44mm       |
| 完成: 阳极氧化       |
| 材料: 铝; 聚酰胺     |
| 包装数量: 1        |

### 其他产品详情

请单独订购垂直安装支架。

### 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**