


托盘把手，尺寸 2

物料号

60225-012

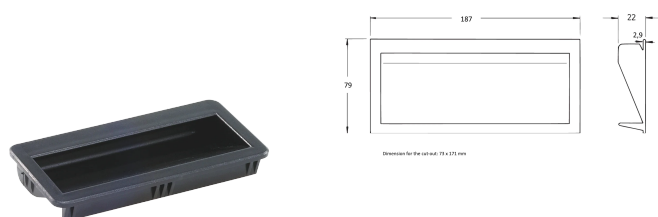

盒式把手可夹在机箱侧面板的开孔中。可提供 2 种尺寸。

认证



功能

静态承载能力 30 千克/对

最小侧面板厚度 1,0 mm

产品属性

高度: 79mm

宽度: 187mm

深度: 22mm

包装数量: 1

手柄类型: 托架把手

可燃性等级: UL® 94V-0

颜色: 黑色

材料: 聚碳酸酯

产品系列: RatiopacPRO; RatiopacPRO AIR; PropacPRO; CompacPRO; Comptec

产品类型: 手柄

静态负载: 30kg

类型: 静态

搭配: 仪器箱

Net Weight: 0.064kg

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

请注意，货物可能以标准包装数量（例如5件、10件、50件等）发货。不同的订购数量（例如2件）可能以下一级标准包装数量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE