


PMC 夹层板的电压编码键/销

物料号

60827-026

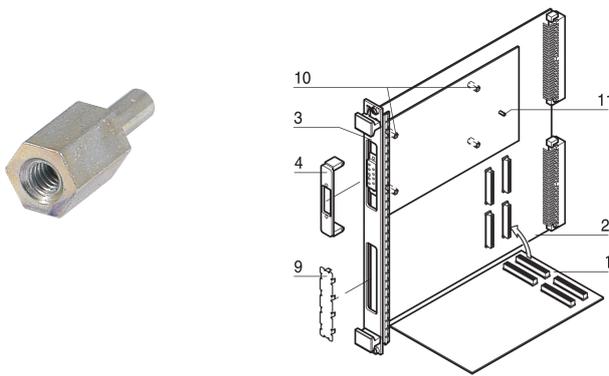

PMC 夹层板的电压键控/编码销。

认证



功能

用于防止固定夹层板时发生意外损坏, 键控/编码销通过螺钉固定至 VMEbus 板, 以区分 3.3 V 和 5 V 工作电压。夹层板的相应位置有一个钻孔。键控/编码销可确保背板仅可接受具有相同工作电压的夹层板。对于双高度欧卡规格电路板, 需要 2 件该元件。

PMC 夹层板的电压键控/编码销

产品属性

产品类型: 编码/键控指示器

产品系列: EuropacPRO; RatiopacPRO; CompacPRO; PropacPRO; Inpac

类型: 编码销钉

搭配: 插箱; 仪器箱; CompactPCI 系统; CompactPCI Serial 系统; PXI

螺纹类型: 公制

材料: 不锈钢

包装数量: 1

深度: 13.5mm

高度: 5mm

长度: 13.5mm

宽度: 5mm

其他产品详情

交货可能按规定 SPQ 执行 (SPQ, 如 5 件, 10 件, 50 件, 等等), 请谨慎选择后下单。我们会将不符合规定的订购数量 (例如 2 件) 更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE