


标准导轨，带 DIN 连接器固定，塑料，槽宽 160 毫米，2 毫米，红色，1 对

物料号

64560-074

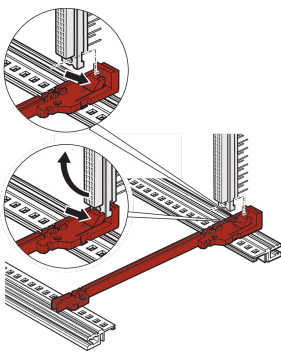

带连接器固定件的标准型导轨有助于用户将 DIN (EN 60603-2 (DIN 41612)) 连接器直接夹在导轨上。仅适用于尺寸为 100 x 160 mm 和 100 x 220 mm 的欧洲规格电路板。适合 RatiopacPRO/-AIR、PropacPRO、CompacPRO 和 EuropacPRO。

认证



功能

通过卡扣连接方便经济地安装连接器，可替代 Z 轨或带集成 Z 轨的水平轨道

适用于单欧洲板规格 100 × 160 mm 或 100 × 220 mm；不适合双欧洲板规格

塑料导轨，单段式，红色，适用于 2 mm 凹槽宽度

可以夹在铝挤压件水平轨道中

可以夹入 1.5 mm 厚板

存储温度：-40 °C ... 130 °C

产品属性

包装数量: 2

板深度: 160mm
槽宽: 2
颜色: 红色
符合: EN 60603-2 (DIN 41612)
材料: 聚对苯二甲酸丁二醇酯
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
产品类型: 导轨
类型: 标配 DIN 连接器
搭配: 插箱; 仪器箱; 机箱
包装单位: 对
Net Weight: 0.021kg

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE