


EuropacPRO 后部固定转接件, DL3 Standard

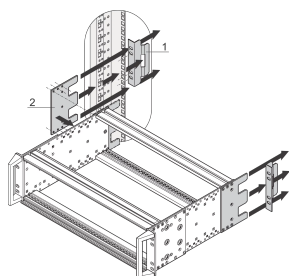

适用于后部固定的转接件，可根据 DL3 标准将插箱固定在机柜中。可保证抗冲击性和抗振动性高达 25 g。

认证



功能

保证抗振动性高达 25g，符合 IEC 61587 DL3 标准

可应要求提供适用于其他机柜型号的转接件

安装在加固型插箱的后侧和 Varistar 机柜支柱上

技术参数

产品类型: 适配器

产品系列: EuropacPRO

搭配: 插箱

Table 1/1

物料号	机架高度	包装数量	完成	材料	快速发货
24568-198	3U	2	镀锌铝, 阳极氧化	钢, 铝	No
24568-498	6U	4	镀锌铝, 阳极氧化	钢, 铝	No

转接件不能与转角型材一起使用。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE