


EuropacPRO Advanced EMC Plus, Dual Mesh Top and Bottom Covers, Screwed to Side Panel

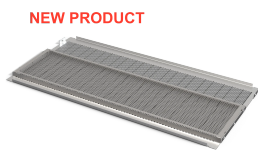

A cover plate is used for electromagnetic shielding and as mechanical protection. The cover can be screwed onto the side panel.

功能

双层网格顶盖和底板带有 EMC 和气流优化穿孔, 适用于最高的射频屏蔽要求

满足防火安全标准 EN 62368-1 的要求

适用于具有标准格式的 PCB

适合以螺栓固定到侧面板的盖板

适合与所有水平导轨搭配使用, 不仅仅是坚固

技术参数

材料:	铝
产品类型:	盖板
产品系列:	EuropacPRO
完成:	钝化
类型:	穿孔
搭配:	插箱

Table 1/1

物料号	深度	包装数量	机架宽度	板深度	包装单位	快速发货
-----	----	------	------	-----	------	------

24563-770	175mm	2	84HP	160mm	对	No
24563-771	235mm	2	84HP	160mm	对	No
24563-772	275mm	2	84HP	160mm	对	No
24563-780	235mm	2	84HP	220mm	对	No
24563-774	295mm	2	84HP	160mm	对	No
24563-781	295mm	2	84HP	220mm	对	No
24563-773	277.75mm	2	84HP	160mm	对	No
24563-775	355mm	2	84HP	160mm	对	No
24563-776	415mm	2	84HP	160mm	对	No
24563-777	475mm	2	84HP	160mm	对	No
24563-782	355mm	2	84HP	220mm	对	No
24563-783	415mm	2	84HP	220mm	对	No
24563-784	475mm	2	84HP	220mm	对	No
24563-790	295mm	2	84HP	280mm	对	No
24563-791	355mm	2	84HP	280mm	对	No
24563-792	415mm	2	84HP	280mm	对	No
24563-793	475mm	2	84HP	280mm	对	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE