


EuropacPRO 盖板, 通用型

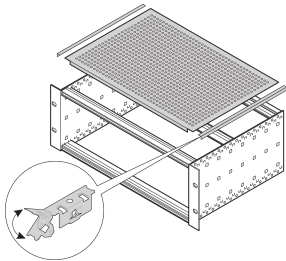

盖板用于提供电磁屏蔽或机械保护。盖板可用于装配到插箱中的非标准板卡。

认证



功能

屏蔽可选 EMC 不锈钢条, 装在盖板和侧板之间

适用于水平横梁的可变定位, 例如用非标准规格的 PCB

通风率 58%

适合与所有水平导轨搭配使用

技术参数

材料: 铝
 产品类型: 盖板
 产品系列: EuropacPRO
 完成: 钝化
 搭配: 插箱
 类型: 通用型

Table 1/1

物料号	机架宽度	深度	包装数量	包装单位	快速发货
-----	------	----	------	------	------

24560-031	42HP	175mm	2	对	No
24560-032	42HP	235mm	2	对	No
24560-033	42HP	295mm	2	对	No
24560-041	63HP	175mm	2	对	No
24560-042	63HP	235mm	2	对	No
24560-043	63HP	295mm	2	对	No
24560-051	84HP	175mm	2	对	No
24560-052	84HP	235mm	2	对	No
24560-053	84HP	295mm	2	对	No
24560-054	84HP	355mm	2	对	No
24560-055	84HP	415mm	2	对	No
24560-056	84HP	475mm	2	对	No

其他产品详情

此外，要将盖板固定至水平轨道，每个插箱需要 4 个屏蔽条。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE