


EuropacPRO 支持不锈钢 EMC 垫片的后罩

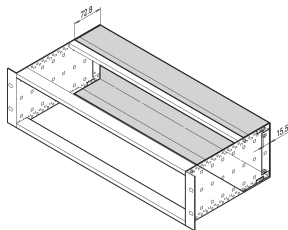

后罩可用作屏蔽型插箱后面，并且需要 60 mm 间隙。因此，如果使用后罩，侧板深度必须比电路板深度多 60 mm。可通过适用该盖板的不锈钢屏蔽条在后罩和水平横梁之间建立接触。因此，无需额外的 EMC 密封件。后罩不能与后角型材同时使用。

认证



功能

后罩可用在屏蔽插箱的后侧。后罩需要 60 mm 间隙。因此，如果使用后罩，侧板深度必须比电路板深度多 60 mm。示例：电路板深度为 160 mm 时，应使用 235 mm (175 mm + 60 mm) 的侧板（带后罩）

可通过适用该盖板的不锈钢屏蔽条在后罩和水平横梁之间建立接触。因此，无需额外的 EMC 屏蔽条。

后罩不能与后角规同时使用

对于 EMC 屏蔽，请单独订购适用于水平横梁的 EMC 屏蔽条。

技术参数

材料:	铝
产品类型:	盖板
产品系列:	EuropacPRO
完成:	钝化
类型:	后罩
搭配:	插箱

Table 1/1

物料号	机架高度	机架宽度	包装数量	快速发货
-----	------	------	------	------

34561-750	3U	42HP	1	No
34561-752	3U	84HP	1	No
34561-763	6U	63HP	1	No
34561-764	6U	84HP	1	No

其他产品详情

Required quantity of screws per rear hood: 3 U subrack 10 screws; 6 U subrack 16 screws.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE