


助拔把手，1 型

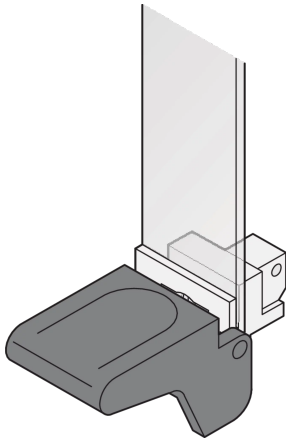

1 型助拔把手，可用于拔出 PCB。把手包括黑色或灰色、顶部和底部版本。

认证



功能

把手 UL 94 V-0, 锌铸造件

在 6 U, 印制板位置可以通过交换上部和下部把手的方式向右侧偏移 1 HP。这可为左侧的 SMD 组件留出空间

请单独订购凸缘螺钉。

技术参数

类型:	助拔器
搭配:	前面板
产品类型:	手柄
材料:	聚碳酸酯

Table 1/1

物料号	颜色	包装数量	手柄类型	可燃性等级	快速发货
-----	----	------	------	-------	------

20817-325	灰色	1	1 型助拔器，底部	UL® 94V-0	No
20817-326	灰色	1	1 型助拔器，顶部	UL® 94V-0	No
20817-345	黑色	1	1 型助拔器，底部	UL® 94V-0	No
20817-346	黑色	1	1 型助拔器，顶部	UL® 94V-0	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE