


EMC 屏蔽前框架，可沿水平方向安装板卡

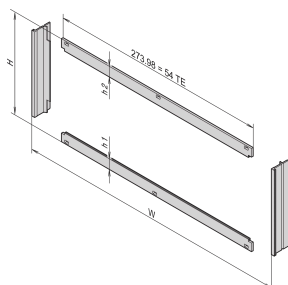

前框架可在插箱与装配件之间提供连接。如果客户选择了水平板安装套件，则必须使用。

认证



功能

前框架提供了插箱与装配件之间的连接。

技术参数

材料: 铝
产品系列: EuropacPRO
产品类型: 侧面板
搭配: 插箱

Table 1/1

物料号	机架高度	机架宽度	包装数量	完成	快速发货
24564-109	3U	20HP	1	阳极氧化, 钝化	No
24564-209	4U	28HP	1	阳极氧化, 钝化	No

其他产品详情

H=128.40 mm，h1=h2= 13.23 mm。

EMC 屏蔽条，不锈钢，参见子组件/前面板。

请单独订购附件。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE