



前面板 1 U, 水平轨道安装

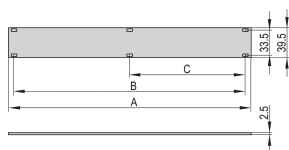

1U前面板便于用户覆盖住下列机箱的1U部分，适用4U PropacPRO仪器箱，5U(1-3-1) RatiopacPRO以及4U EuropacPRO。该面板将被组装到水平横梁上的螺母条里面。

认证

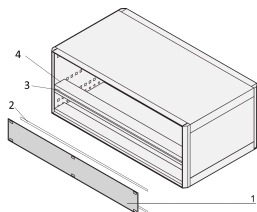

功能

安装在水平横梁上（上，下）

技术参数

材料:	铝
完成:	阳极氧化; 钝化
产品系列:	RatiopacPRO; PropacPRO; EuropacPRO
附件类型:	前面板
产品类型:	前面板


Table 1/2

物料号	机架高度	高度 (H)	机架宽度	宽度 (W)	深度 (D)	包装数量
-----	------	--------	------	--------	--------	------

20850-423	1U	39.5mm	28HP	141.9mm	2.5mm	1
20850-424	1U	39.5mm	42HP	213mm	2.5mm	1
20850-425	1U	39.5mm	63HP	319.7mm	2.5mm	1
20850-426	1U	39.5mm	84HP	426.4mm	2.5mm	1

Table 2/2				
物料号	正面表面处理	反面表面处理	边缘处理	快速发货
20850-423	阳极氧化	导电	否	No
20850-424	阳极氧化	导电	否	No
20850-425	阳极氧化	导电	否	No
20850-426	阳极氧化	导电	否	No

图

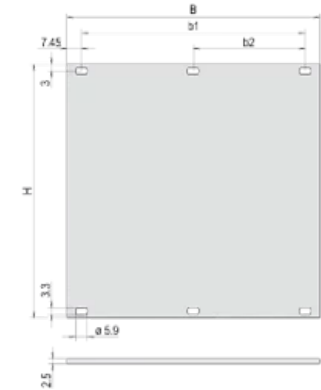

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE