

前面板, 阳极氧化, 非屏蔽型, 螺钉组件

阳极氧化前面板, 非屏蔽版本, 铝 2.5 mm。



认证



功能

非全宽前面板, 铝, 2.5 mm

铝, 阳极氧化

技术参数

深度 (D): 2.5mm
材料: 铝
完成: 阳极氧化
附件类型: 前面板
产品类型: 前面板
类型: 不带把手的前面板

Table 1/3

物料号	机架高度	机架宽度	包装数量	安装	正面表面处理	反面表面处理
30807-508	3U	3HP	1	正面螺钉安装	阳极氧化	阳极氧化

物料号	机架高度	机架宽度	包装数量	安装	正面表面处理	反面表面处理
30807-481	3U	4HP	1	正面螺钉安装	阳极氧化	阳极氧化
30818-741	6U	2HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-510	3U	5HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-482	3U	6HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-509	3U	7HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-484	3U	8HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-483	3U	10HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-777	6U	5HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-485	3U	12HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-752	6U	6HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-501	3U	14HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-833	6U	7HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-779	6U	8HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-487	3U	21HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-753	6U	10HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-755	6U	12HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-496	3U	28HP	1	正面螺钉安装	阳极氧化	阳极氧化

物料号	机架高度	机架宽度	包装数量	安装	正面表面处理	反面表面处理
30807-758	6U	14HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-780	6U	16HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-494	3U	42HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-757	6U	21HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-416	2U	84HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-766	6U	28HP	1	正面螺钉安装	阳极氧化	阳极氧化
30808-067	3U	63HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-506	3U	84HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-764	6U	42HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-596	4U	84HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-771	6U	63HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-776	6U	84HP	1	正面螺钉安装	阳极氧化	阳极氧化
30807-778	6U	4HP	1	正面螺钉安装	阳极氧化	阳极氧化
30810-432	3U	2HP	1	正面螺钉安装	阳极氧化	阳极氧化

Table 2/3						
物料号	边缘处理	符合	EMC 屏蔽	高度 (H)	宽度 (W)	认证
30807-508	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	14.9mm	RoHS

物料号	边缘处理	符合	EMC 屏蔽	高度 (H)	宽度 (W)	认证
30807-481	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	20mm	RoHS
30818-741	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	9.8mm	RoHS
30807-510	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	25mm	RoHS
30807-482	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	30.1mm	RoHS
30807-509	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	35.2mm	RoHS
30807-484	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	40.3mm	RoHS
30807-483	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	50.5mm	RoHS
30807-777	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	25mm	RoHS
30807-485	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	60.6mm	RoHS
30807-752	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	30.1mm	RoHS
30807-501	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	70.8mm	RoHS
30807-833	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	35.2mm	RoHS

物料号	边缘处理	符合	EMC 屏蔽	高度 (H)	宽度 (W)	认证
30807-779	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	40.3mm	RoHS
30807-487	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	106.3mm	RoHS
30807-753	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	50.5mm	RoHS
30807-755	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	60.6mm	RoHS
30807-496	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	141.9mm	RoHS
30807-758	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	70.8mm	RoHS
30807-780	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	80.9mm	RoHS
30807-494	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	213mm	RoHS
30807-757	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	106.3mm	RoHS
30807-416	是	IEC 60297-3-101, IEEE 1101.1/10	否	84mm	426.4mm	RoHS
30807-766	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	141.9mm	RoHS
30808-067	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	319.7mm	RoHS

物料号	边缘处理	符合	EMC 屏蔽	高度 (H)	宽度 (W)	认证
30807-506	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	426.4mm	RoHS
30807-764	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	213mm	RoHS
30807-596	是	IEC 60297-3-101, IEEE 1101.1/10	否	172.9mm	426.4mm	
30807-771	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	319.7mm	RoHS
30807-776	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	426.4mm	RoHS
30807-778	是	IEC 60297-3-101, IEEE 1101.1/10	否	261.8mm	20mm	RoHS
30810-432	是	IEC 60297-3-101, IEEE 1101.1/10	否	128.4mm	9.8mm	RoHS


Table 3/3	
物料号	快速发货
30807-508	No
30807-481	No
30818-741	No
30807-510	No
30807-482	No
30807-509	No

物料号	快速发货
30807-484	No
30807-483	No
30807-777	No
30807-485	No
30807-752	No
30807-501	No
30807-833	No
30807-779	No
30807-487	No
30807-753	No
30807-755	No
30807-496	No
30807-758	No
30807-780	No
30807-494	No
30807-757	No
30807-416	No

物料号	快速发货
30807-766	No
30808-067	No
30807-506	No
30807-764	No
30807-596	No
30807-771	No
30807-776	No
30807-778	No
30810-432	No

其他产品详情

请单独订购紧固零件（螺钉套，凸缘螺钉）。

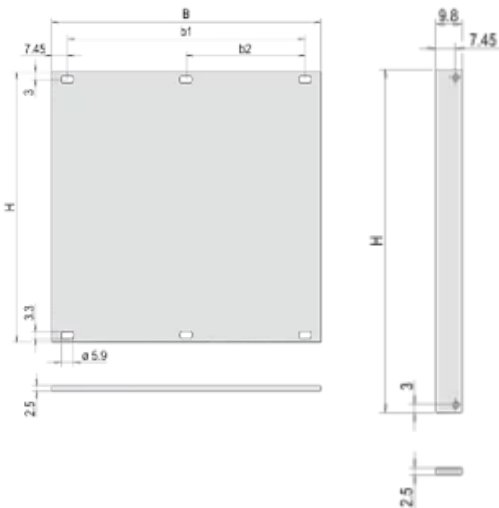

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE